

Data Sheet

Steel Switchboard cabinet



Specifications

- Housing: Steel sheet
- Door: Steel sheet, foamed-in PU seal all around
- Material thickness: Housing 1.2 mm
- Door 1.5 mm
- Mounting plate 2 mm
- Mounting material: Aluminum coated zinc plate
- IP rating: IP65
- Type: Single-door (Lock on the left)
- Colour: Grey-white
- Includes: Key, Screws, Mounting plate, Mounting bracket


Item Number	Product Size(H x W x D)	Product weight
3219013	400 x 300 x 200mm	11kg
3219014	400 x 400 x 200mm	13kg
3219015	500 x 400 x 200mm	15kg
3219016	500 x 500 x 200mm	17.5kg
3219017	600 x 500 x 200mm	20kg
3219018	600 x 600 x 200mm	23kg

Sheet steel switchboard cabinet with cam lock and one gland plate

BN:3219013

UNIT:MM

Ratio: 1:1

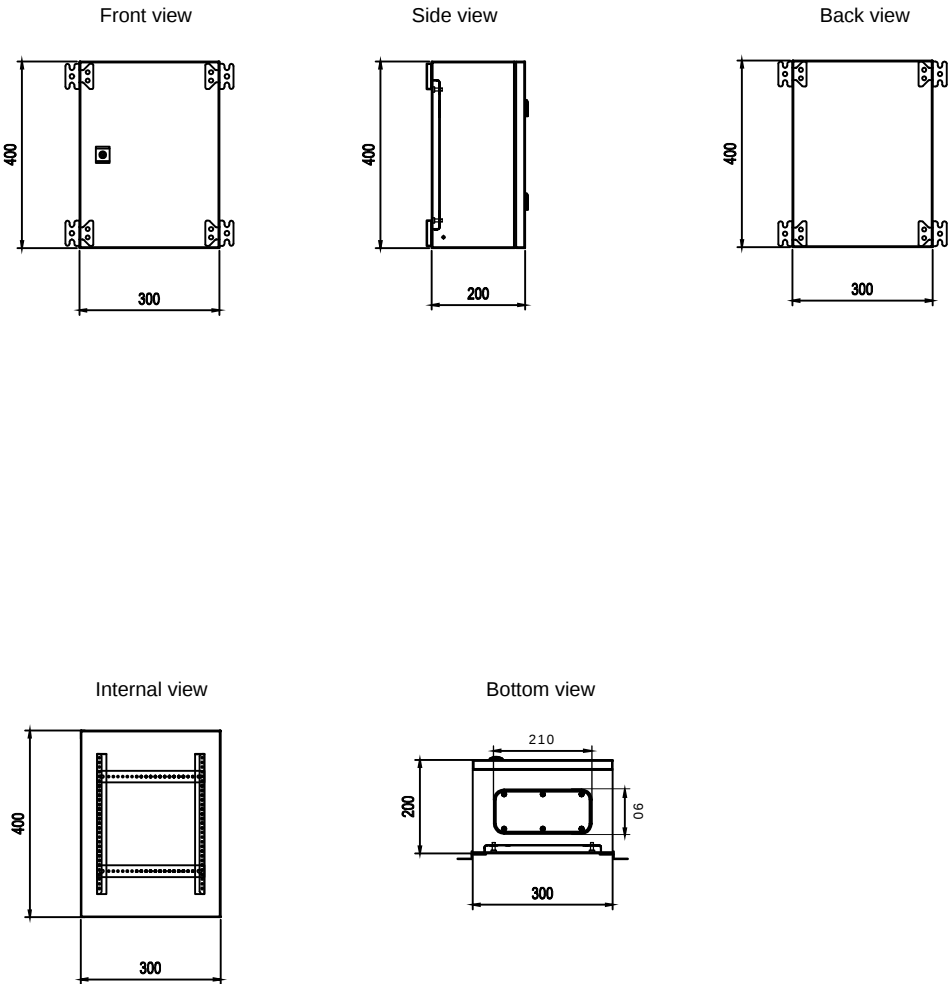


Sheet steel switchboard cabinet with cam lock and one gland plate

BN:3219014


UNIT:MM

Ratio: 1:1


Front view

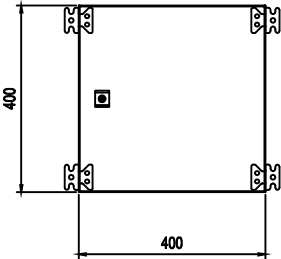


Side view

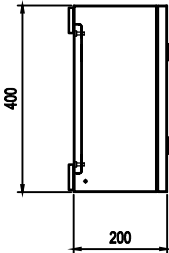


Back view

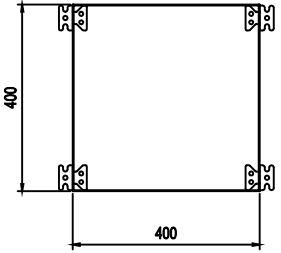

Internal view

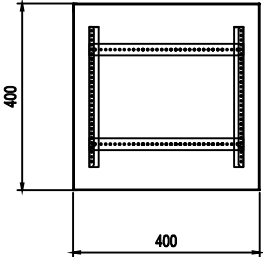

Bottom view

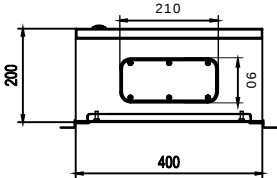


Sheet steel switchboard cabinet with cam lock and one gland plate

BN:3219015


UNIT:MM

Ratio: 1:1


Front view

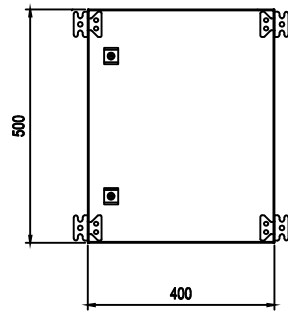


Side view

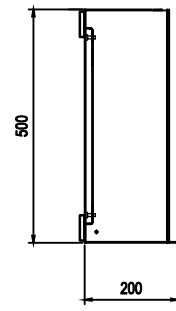


Back view

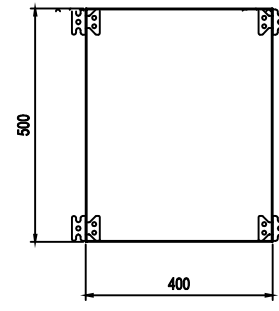

Internal view

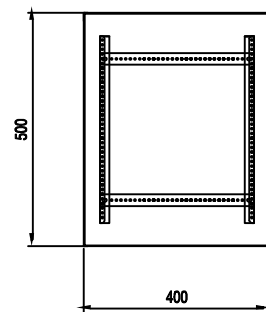

Bottom view

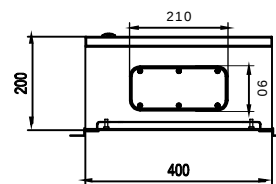


Sheet steel switchboard cabinet with cam lock and one gland plate

BN:3219016


UNIT:MM

Ratio: 1:1


Front view

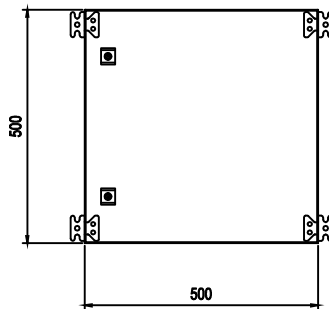


Side view

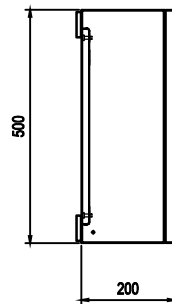


Back view

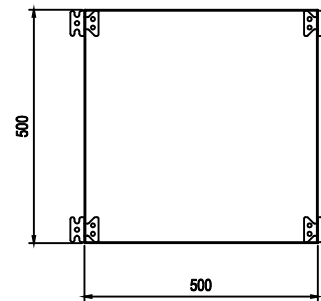

Internal view

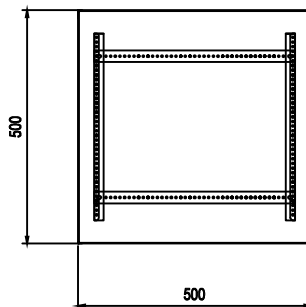

Bottom view

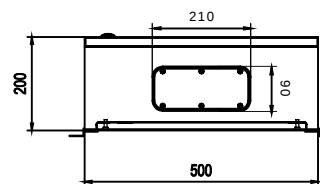


Sheet steel switchboard cabinet with cam lock and one gland plate

BN:3219017


UNIT:MM

Ratio: 1:1


Front view

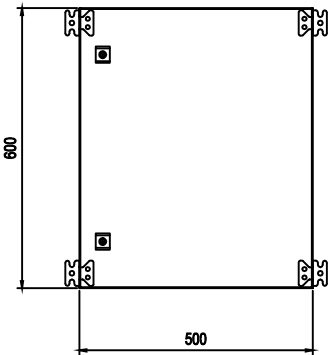


Side view

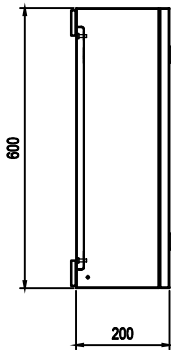


Back view

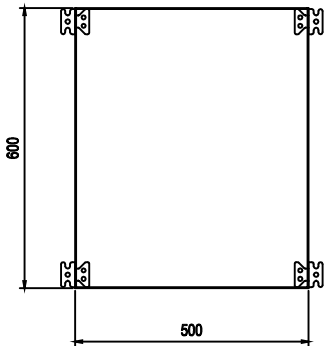

Internal view

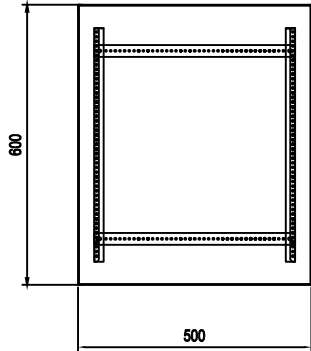

Bottom view

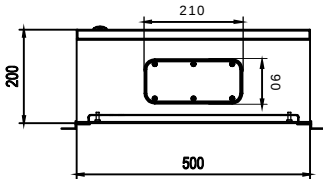

Sheet steel switchboard cabinet with cam lock and one gland plate

BN:3219018

UNIT:MM

Ratio: 1:1

