

Data Sheet

Stainless steel Switchboard cabinet



Specifications

- Housing: 304 Stainless steel sheet
- Door: 304 Stainless steel sheet, foamed-in PU seal all around
- Material thickness: Housing 1.2 mm
- Door 1.5 mm
- Mounting plate 2 mm
- Mounting material: Aluminum coated zinc plate
- IP rating: IP65
- Type: Single-door (Lock on the left)
- Colour: Silver
- Includes: Key, Screws, Mounting plate, Mounting bracket

Item Number	Product Size(H x W x D)	Product weight
3219019	400 x 300 x 200mm	11kg
3219020	400 x 400 x 200mm	13kg
3219021	500 x 400 x 200mm	15kg
3219022	500 x 500 x 200mm	17.5kg
3219023	600 x 500 x 200mm	20kg
3219024	600 x 600 x 200mm	23kg


Stainless sheet steel switchboard cabinet with cam lock and three wiring holes

BN:3219019


UNIT:MM

Ratio: 1:1


Front view

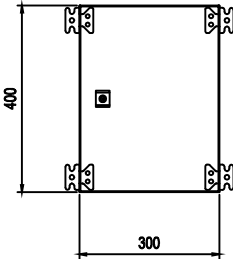


Side view

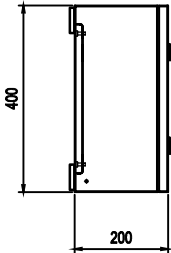


Back view

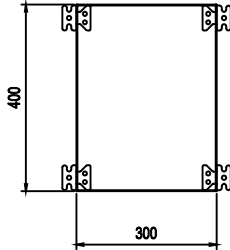

Internal view

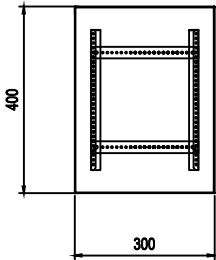

Bottom view

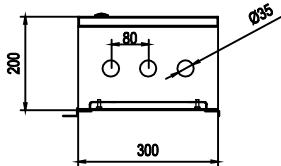


Stainless sheet steel switchboard cabinet with cam lock and four wiring holes

BN:3219020

UNIT:MM

Ratio: 1:1

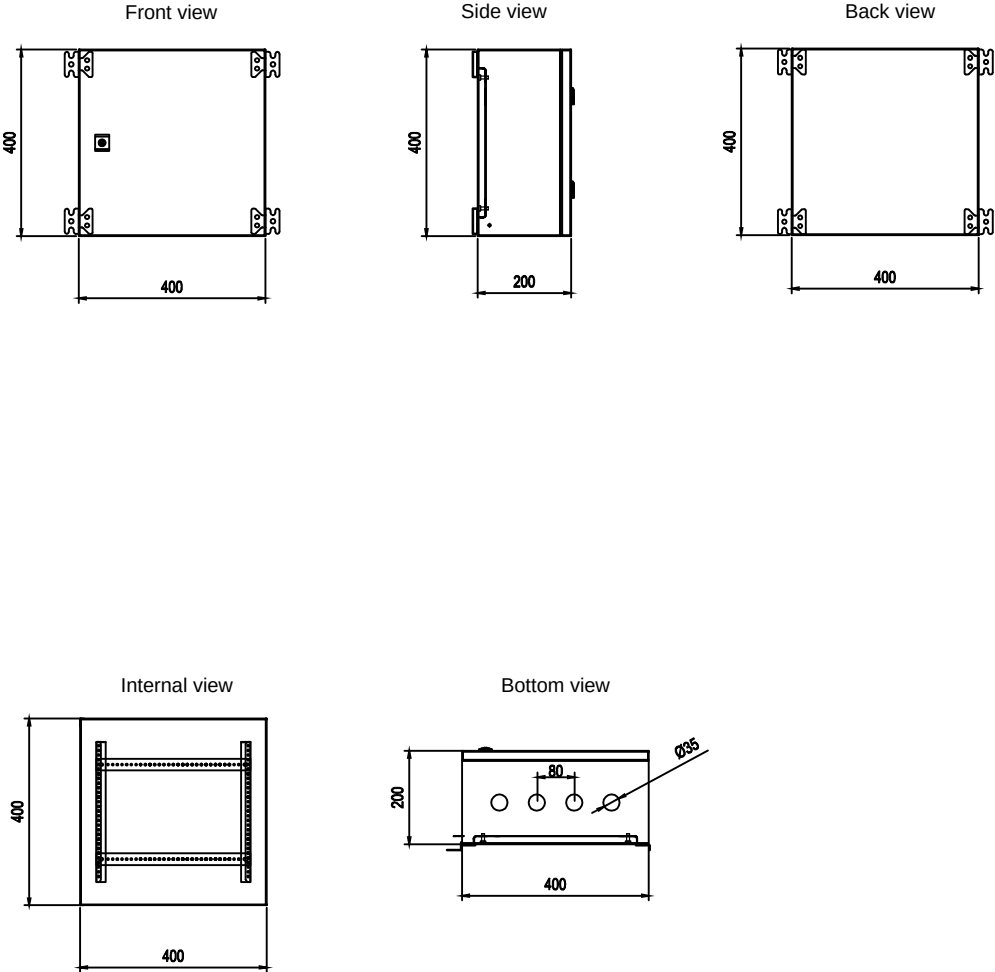


Stainless sheet steel switchboard cabinet with cam lock and four wiring holes

BN:3219021

UNIT:MM

Ratio: 1:1

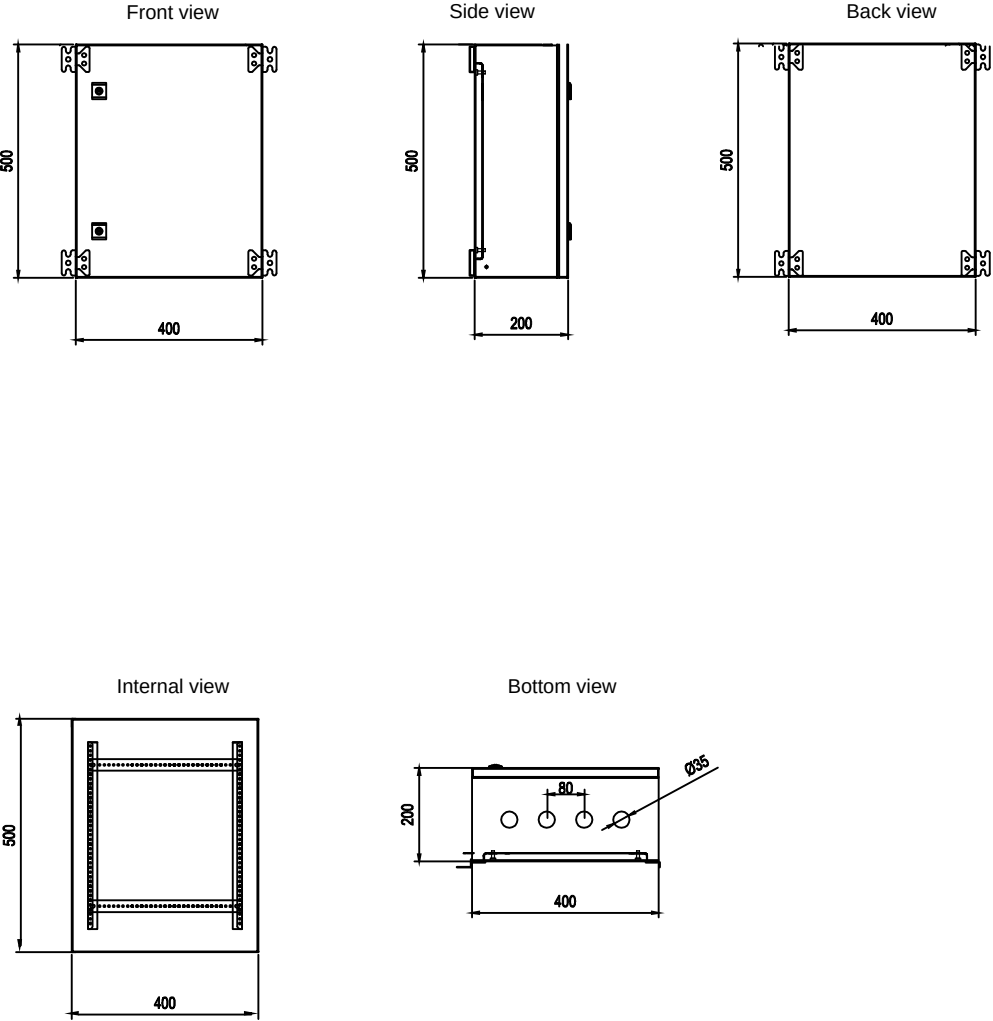

A


Stainless sheet steel switchboard cabinet with cam lock and five wiring holes

BN:3219022


UNIT:MM

Ratio: 1:1

B

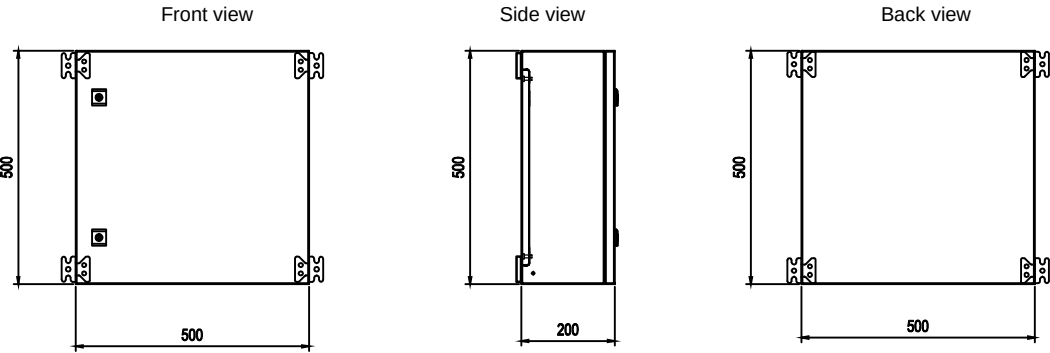

C

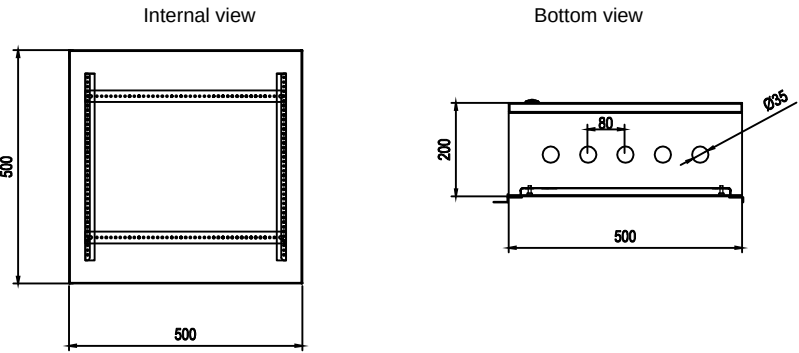

D

1

2

3

4

5

6


Stainless sheet steel switchboard cabinet with cam lock and five wiring holes

BN:3219023


UNIT:MM

Ratio: 1:1


Front view

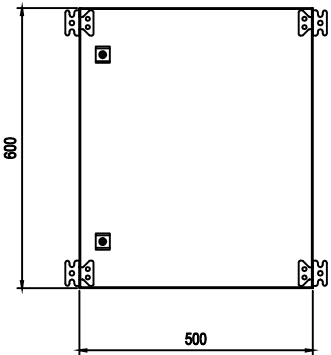


Side view

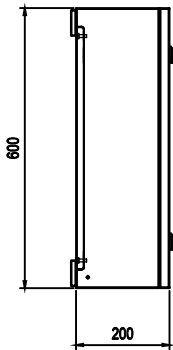


Back view

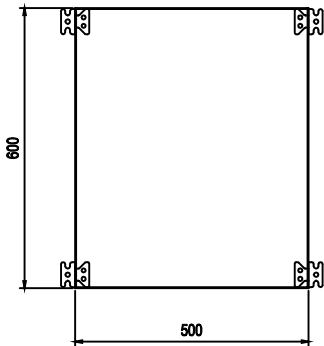

Internal view

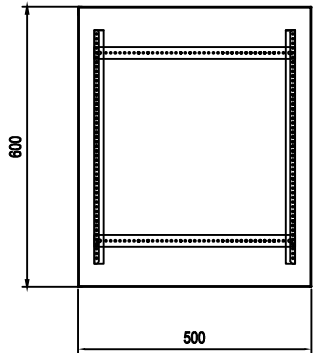

Bottom view

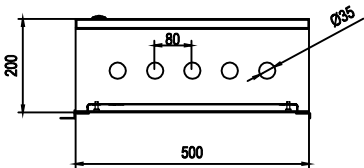

Stainless sheet steel switchboard cabinet with cam lock and six wiring holes

BN:3219024

UNIT:MM

Ratio: 1:1

