




USB 3.1 Type C® Male Connector to 5 way terminals,
Pluggable adapter, screw termination, Length 300mm
terminator to terminator BN 3221976

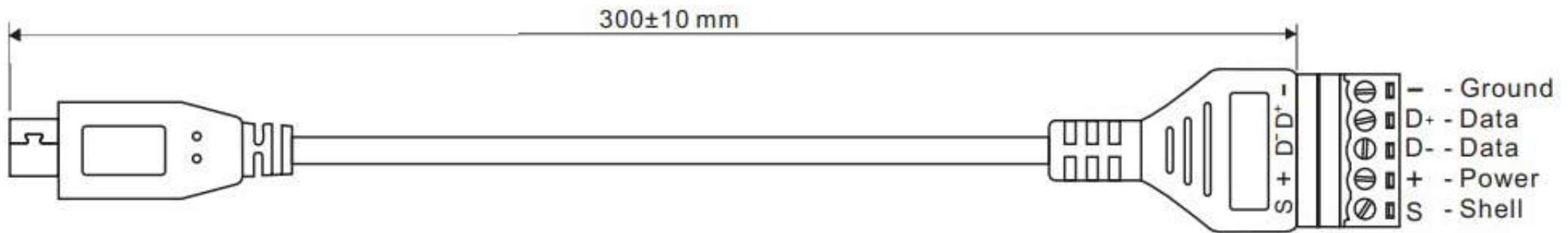

USB Type
Outer sheath material
Sheath Color
Voltage rating
Current rating
Suits wire range
Operating temperature
Operating humidity
Storage temperature
Storage humidity

USB Type-C, Male
PVC
Black
20 V/DC
3A max.
AWG 26-20 (0.15-0.5mm²)
-10 to +85°C
95% RH max.
-10 to +60°C
15 - 60% RH