




USB 3.1 Type C® Female Connector to 5 way terminals, Pluggable adapter,
screw termination, Length 300mm terminator to terminator
BN 3221977

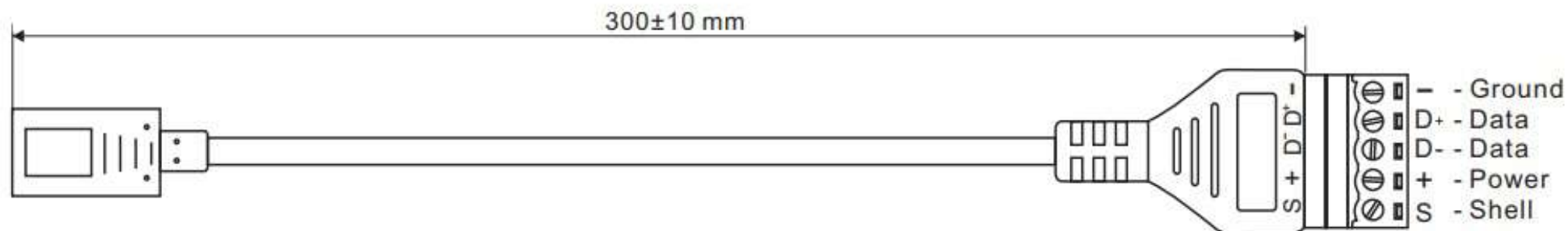

USB Type	USB Type-C, Female
Outer sheath material	PVC
Sheath Color	Black
Voltage rating	20 V/DC
Current rating	3A max.
Suits wire range	AWG 26-20 (0.15-0.5mm ²)
Operating temperature	-10 to +85°C
Operating humidity	95% RH max.
Storage temperature	-10 to +60°C
Storage humidity	15 - 60% RH