




MICRO USB Female Connector to 5 way terminals, Pluggable adapter, screw termination, Length 300mm, terminator to terminator BN 3221979

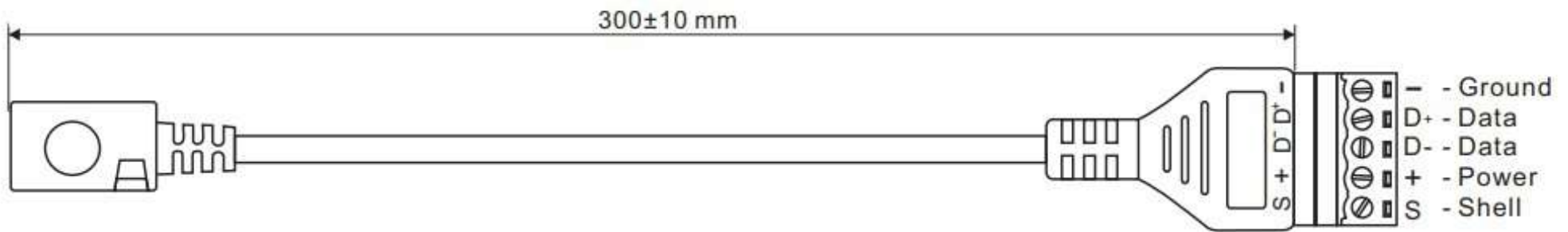

|                       |                                      |
|-----------------------|--------------------------------------|
| USB Type              | Micro-B, Female                      |
| Outer sheath material | PVC                                  |
| Sheath Color          | Black                                |
| Voltage rating        | 30 V AC(RMS)/DC                      |
| Current rating        | 1.0 A                                |
| Suits wire range      | AWG 26-20 (0.15-0.5mm <sup>2</sup> ) |
| Operating temperature | -10 to +85°C                         |
| Operating humidity    | 95% RH max.                          |
| Storage temperature   | -10 to +60°C                         |
| Storage humidity      | 15 - 60% RH                          |