




USB 2.0 Type-B Male Connector to 5 way terminals, Pluggable adapter,
screw termination, length 300mm terminator to terminator BN 3221982

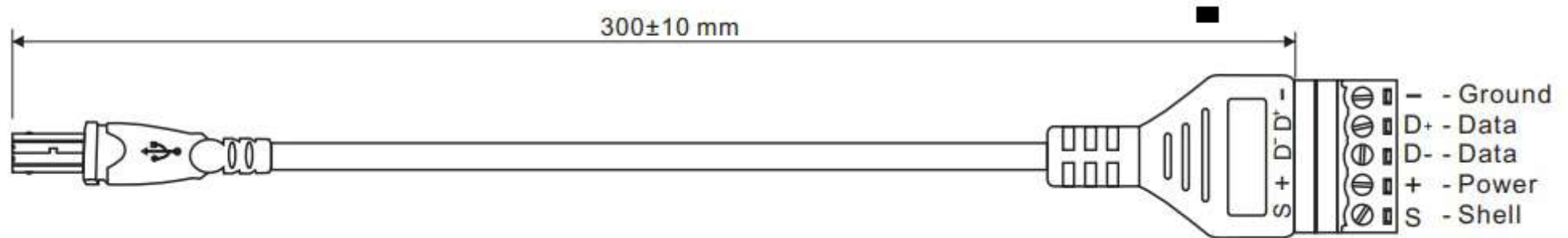

USB Type	Type-B, Male
Outer sheath material	PVC
Sheath Color	Black
Voltage rating	30 V AC(RMS)/DC
Current rating	1.5 A
Suits wire range	AWG 26-20 (0.15-0.5mm ²)
Operating temperature	-10 to +85°C
Operating humidity	95% RH max.
Storage temperature	-10 to +60°C
Storage humidity	15 - 60% RH