




USB 3.1 Type C® Male U-shaped connector to 5 way terminals,
Pluggable adapter, screw termination, Cable length 300mm
terminator to terminator BN 3221985

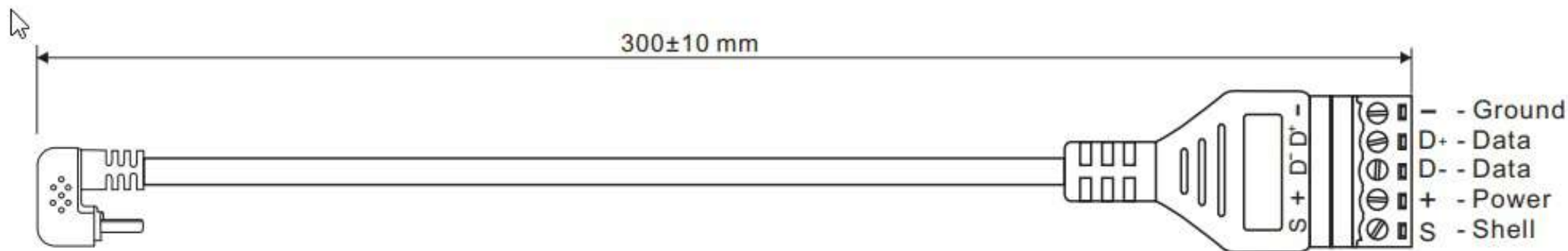

USB Type	Type-C, Male
Outer sheath material	PVC
Sheath Color	Black
Voltage rating	20 V/DC
Current rating	3.0 A
Suits wire range	AWG 26-20 (0.15-0.5mm ²)
Operating temperature	-10 to +85°C
Operating humidity	95% RH max.
Storage temperature	-10 to +60°C
Storage humidity	15 - 60% RH