



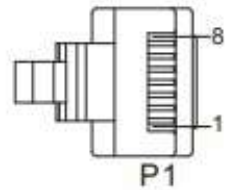

RJ45 8P8C right angle Plug Connector to 8 way terminals, Pluggable adapter, screw termination, length 300mm terminator to terminator BN 3221987

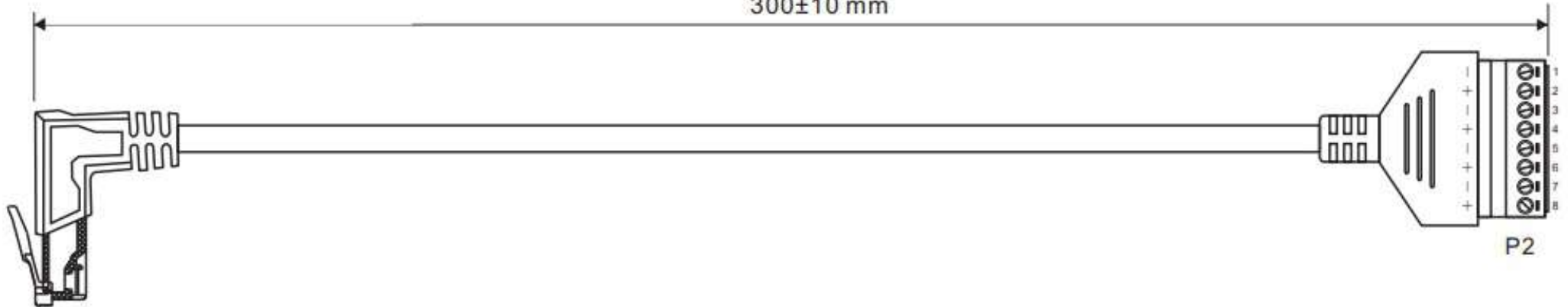

300±10 mm



P1	P2
1	1
2	2
3	3
4	4
5	5
6	6
7	7
8	8

Connector Type	RJ 45, Male
Outer sheath material	PVC
Sheath Color	Black
Voltage rating	12 V/DC
Current rating	1.5 A
Suits wire range	AWG 26-20 (0.15-0.5mm ²)
Operating temperature	-10 to +85°C
Operating humidity	95% RH max.
Storage temperature	-10 to +60°C
Storage humidity	15 - 60% RH