
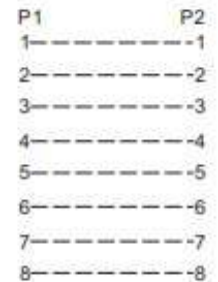
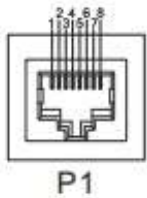


RJ45 8P8C Female Socket to 8 way terminals, Pluggable adapter, screw termination, Cable length 300mm, terminator to terminator BN 3221988

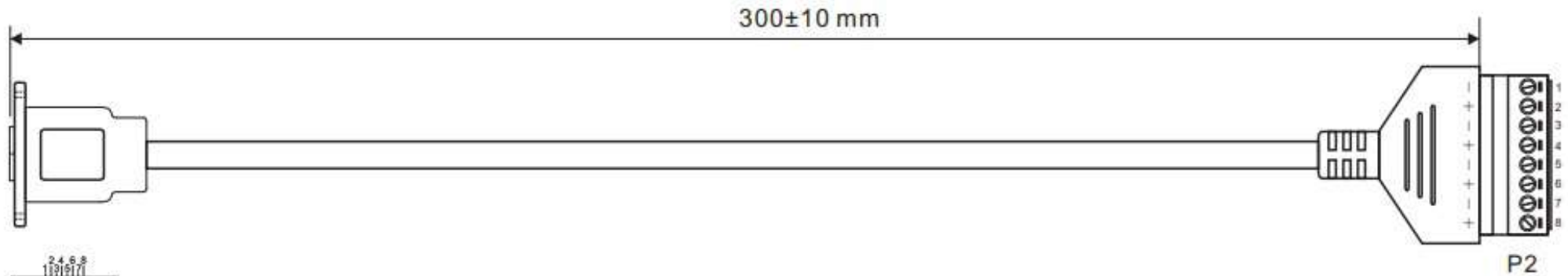

Connector Type	RJ 45, Female
Outer sheath material	PVC
Sheath Color	Black
Voltage rating	12 V/DC
Current rating	1.5 A
Suits wire range	AWG 26-20 (0.15-0.5mm ²)
Operating temperature	-10 to +85°C
Operating humidity	95% RH max.
Storage temperature	-10 to +60°C
Storage humidity	15 - 60% RH