


Data sheet Product SL 10 SMD 040 8 G B SM

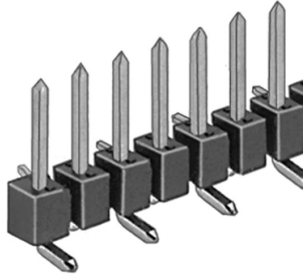

PCB connectors>Male headers

□ 0.635 mm, SMD-technique

... **packing (option) - additions:**

SL 10 SMD 040 - 104 ... SM; ... B SM: 4-20 contacts


SL 10 SMD 040 - 062 ... B TR: 4-20 contacts, 250 pcs/reel

SL 10 SMD 078 ... B TR: 4-12 contacts, 250 pcs/reel

SL 10 SMD 104 - 130 ... B TR: 4-12 contacts, 150 pcs/reel

Features

pitch:	2.54 mm
no. of contacts:	8
contact material:	CuSn-alloy
surface of contact:	gold-plated
surface contact / contact sleeve:	• Ni+≥0.2µm Au • Ni+4...6µm Sn
version:	male header
volume resistance:	≤5 mΩ
nominal current:	3 A
nominal voltage:	250 V AC
test voltage:	2000 V
insulating body material:	PA 4.6. GF
temperature range:	• -40°C... +163°C • (260°C/10 s)
class of inflammability:	UL 94 V-0
specific insulation resistance:	>10 ⁷ Ω·m
connection type:	SMD
reflow solderable:	yes
packing (optional):	pick and place pad and bar magazine

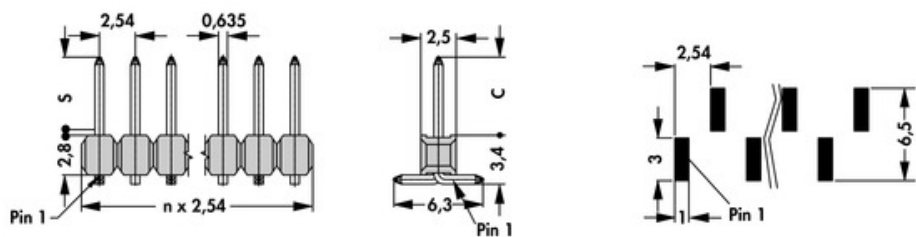

C:


4 mm

S:


4.0 mm

Equipping

- reel diameter Ø 330 mm

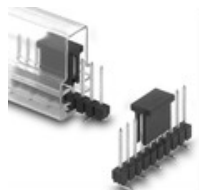

... SM
... B SM

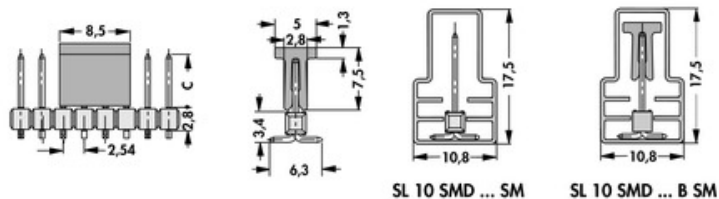


SL 10 SMD ... SM

SL 10 SMD ... B SM



... B TR

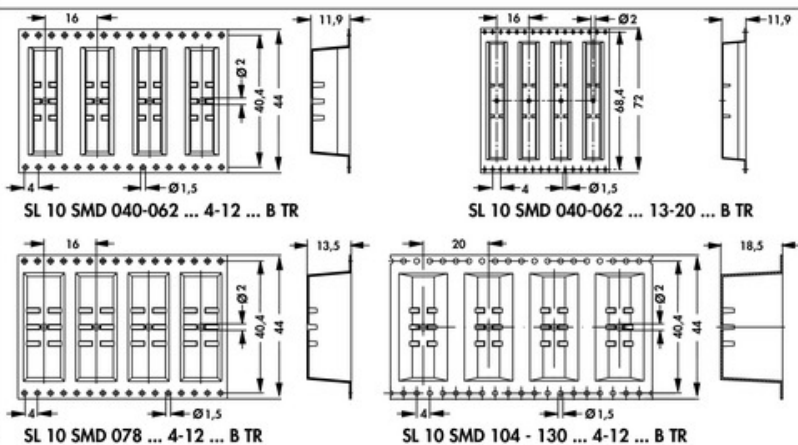

SL 10 SMD 040-062 ... 4-12 ... B TR

SL 10 SMD 040-062 ... 13-20 ... B TR

SL 10 SMD 078 ... 4-12 ... B TR

SL 10 SMD 104 - 130 ... 4-12 ... B TR