

Data sheet Product SL 11 SMD 052 20 S B TR



PCB connectors>Male headers

□ 0.635 mm

... packing (option) - additions:

SL 11 SMD 040-104 ... SM; ... B SM: 6-40 contacts


SL 11 SMD 040-062 ... B TR: 26-40 contacts, 250 pcs/reel

SL 11 SMD 040-078 ... B TR: 6-24 contacts, 250 pcs/reel

SL 11 SMD 104-130 ... B TR: 6-24 contacts, 150 pcs/reel

Features

pitch:	2.54 x 2.54 mm
no. of contacts:	20
contact material:	CuSn-alloy
surface of contact:	selective gold-plated
surface contact / contact sleeve:	• Ni+≥0.2µm Au • Ni+4...6µm Sn
version:	male header
volume resistance:	≤5 mΩ
nominal current:	3 A
nominal voltage:	250 V AC
test voltage:	2000 V
insulating body material:	PA 4.6. GF
temperature range:	• -40°C... +163°C • (260°C/10 s)
class of inflammability:	UL 94 V-0
specific insulation resistance:	>10 ⁷ Ω·m
connection type:	SMD
reflow solderable:	yes
packing (optional):	pick and place pad and tape and reel (250pcs/reel)

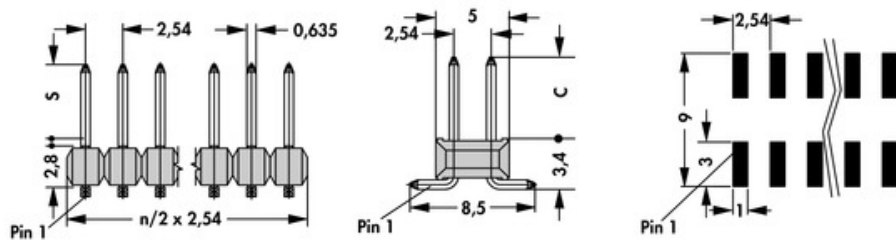

C:

5.5 mm

S:

4.0 mm

Equipping

