

Data sheet Product SL 14 122 44 G




PCB connectors>Male headers
□ 0.635 mm, Sandwich

Features

pitch:	2.54 x 2.54 mm
no. of contacts:	44
contact material:	CuSn-alloy
surface of contact:	gold-plated
surface contact / contact sleeve:	• Ni+≥0.2µm Au • Ni+4...6µm Sn
version:	sandwich
volume resistance:	≤5 mΩ
nominal current:	3 A
nominal voltage:	250 V AC
test voltage:	2000 V
insulating body material:	PA 4.6. GF
temperature range:	• -40°C... +163°C • (260°C/10 s)
class of inflammability:	UL 94 V-0
specific insulation resistance:	>10 ⁷ Ω·m
connection type:	THT (soldering)
reflow solderable:	yes

Technical Drawing

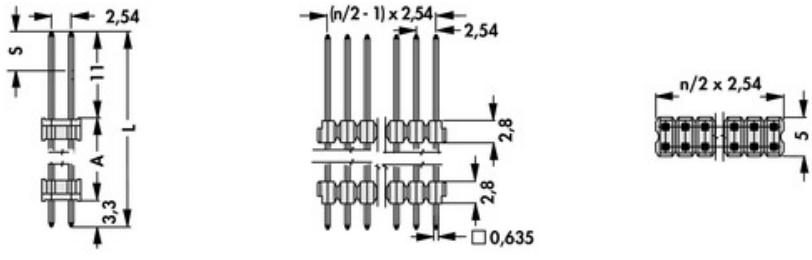

A:	12.2 mm
L	26.5 mm
:	
S:	6.0 mm