

Data sheet Product SL 2 025 14 G




PCB connectors>Male headers
two rows, □ 0.635 mm

Features

pitch:	2.54 x 2.54 mm
no. of contacts:	14
contact material:	CuSn-alloy
surface of contact:	gold-plated
surface contact / contact sleeve:	• Ni+≥0.2µm Au • Ni+4...6µm Sn
version:	standard
volume resistance:	≤5 mΩ
nominal current:	3 A
nominal voltage:	250 V AC
test voltage:	2000 V
insulating body material:	PA 4.6. GF
temperature range:	• -40°C... +163°C • (260°C/10 s)
class of inflammability:	UL 94 V-0
specific insulation resistance:	>10 ⁷ Ω·m
connection type:	THT (soldering)
reflow solderable:	yes

Technical Drawing

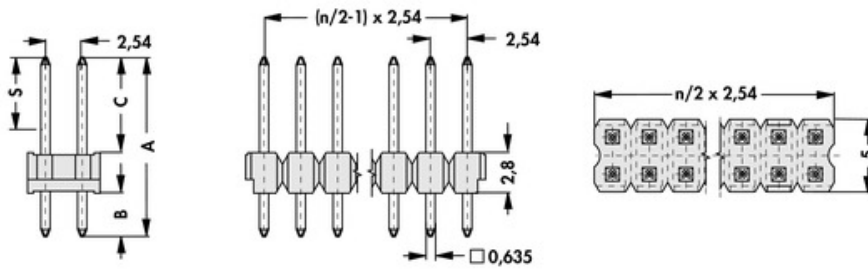

A:	11.2 mm
B:	2.6 mm
C:	5.8 mm
S:	4.0 mm