


Data sheet Product SLV W 3 SMD 073 17 G SM

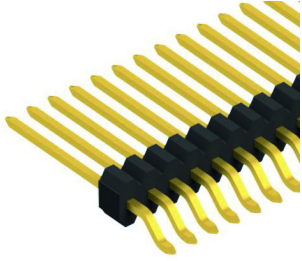


PCB connectors>Male headers
 one row expanded insulator 2-20 contacts, \square 0.4 mm
 matching for female header BLM
 ... packing (option) - additions:
SLV W 3 SMD ... SM: 4-20 contacts
 Packaging options pick and place pad in bar magazine "... B SM" and pick and place pad in tape & reel "... B TR" on request.

Features


pitch:	1.27 mm
no. of contacts:	17
contact material:	CuZn-alloy
surface of contact:	gold-plated
surface contact / contact sleeve:	<ul style="list-style-type: none"> • Ni+\geq0.2μm Au • Ni+4...6μm Sn
version:	male header
volume resistance:	\leq 5 m Ω
nominal current:	1.5 A
nominal voltage:	125 V AC
test voltage:	300 V
insulating body material:	PA 4.6. GF
temperature range:	<ul style="list-style-type: none"> • -40°C... +163°C • (260°C/10 s)
class of inflammability:	UL 94 V-0
specific insulation resistance:	$>10^7$ $\Omega \cdot m$
connection type:	SMD
reflow solderable:	yes
packing (optional):	bar magazine

Technical Drawing

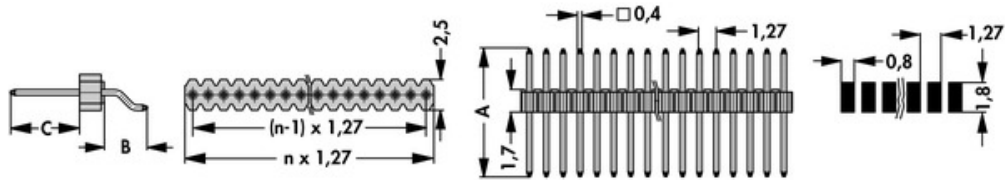


A:	12 mm
B:	3 mm
C:	7.3 mm

Equipping

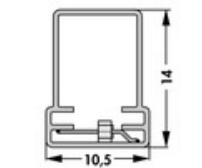

SLV W 3 SMD 048 ... SM

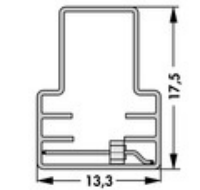

SLV W 3 SMD 073 ... SM

Fischer Elektronik GmbH & Co. KG
 DEUTSCHLAND • GERMANY • ALLEMAGNE

Nottebohmstraße 28
 58511 Lüdenscheid

Telefon +49 2351 435-0
 Telefax +49 2351 45754

info@fischerelektronik.de
 www.fischerelektronik.de