


# Data sheet Product SLV W 3 SMD 073 4 Z SM

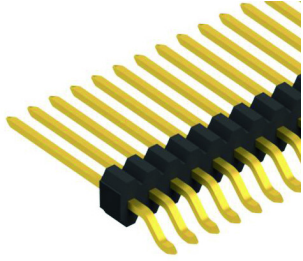


PCB connectors>Male headers  
 one row expanded insulator 2-20 contacts,  $\square$  0.4 mm  
 matching for female header BLM  
 ... packing (option) - additions:  
**SLV W 3 SMD ... SM: 4-20 contacts**  
 Packaging options pick and place pad in bar magazine "... B SM" and pick and place pad in tape & reel "... B TR" on request.

## Features


pitch:	1.27 mm
no. of contacts:	4
contact material:	CuZn-alloy
surface of contact:	tin-plated
surface contact / contact sleeve:	<ul style="list-style-type: none"> <li>• Ni+<math>\geq</math>0.2<math>\mu</math>m Au</li> <li>• Ni+4...6<math>\mu</math>m Sn</li> </ul>
version:	male header
volume resistance:	$\leq$ 5 m $\Omega$
nominal current:	1.5 A
nominal voltage:	125 V AC
test voltage:	300 V
insulating body material:	PA 4.6. GF
temperature range:	<ul style="list-style-type: none"> <li>• -40°C... +163°C</li> <li>• (260°C/10 s)</li> </ul>
class of inflammability:	UL 94 V-0
specific insulation resistance:	$>10^7 \Omega \cdot m$
connection type:	SMD
reflow solderable:	yes
packing (optional):	bar magazine

## Technical Drawing

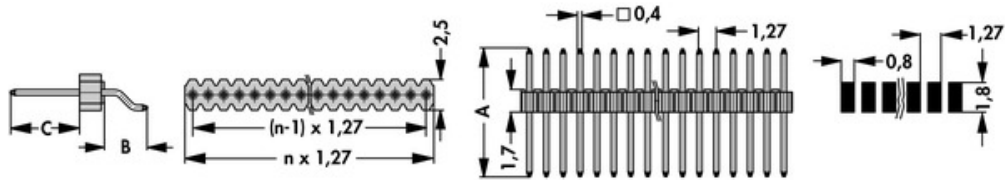


A:	12 mm
B:	3 mm
C:	7.3 mm

## Equipping

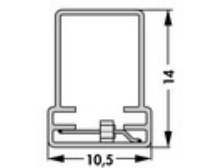

SLV W 3 SMD 048 ... SM

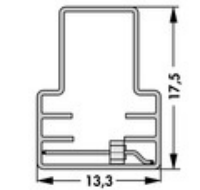

SLV W 3 SMD 073 ... SM

**Fischer Elektronik GmbH & Co. KG**  
DEUTSCHLAND • GERMANY • ALLEMAGNE

Nottebohmstraße 28  
58511 Lüdenscheid

Telefon +49 2351 435-0  
Telefax +49 2351 45754

info@fischerelektronik.de  
www.fischerelektronik.de