


Data sheet Product SLY 7 SMD 045 20 S B SM

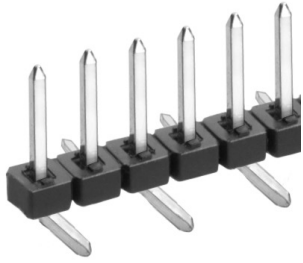


PCB connectors>Male headers

□ 0.5 mm; ... **packing (option) - additions:**
SLY 7 SMD 036-045 ... B TR: 4-15 contacts

Features

pitch:	2.00 mm
no. of contacts:	20
contact material:	CuSn-alloy
surface of contact:	selective gold-plated
surface contact / contact sleeve:	• Ni+≥0.2µm Au • Ni+4...6µm Sn
version:	male header
volume resistance:	≤5 mΩ
nominal current:	3 A
nominal voltage:	100 V DC
test voltage:	500 V
insulating body material:	PA 4.6. GF
temperature range:	• -40°C... +163°C • (260°C/10 s)
class of inflammability:	UL 94 V-0
specific insulation resistance:	>10 ⁷ Ω·m
connection type:	SMD
reflow solderable:	yes
packing (optional):	pick and place pad and bar magazine

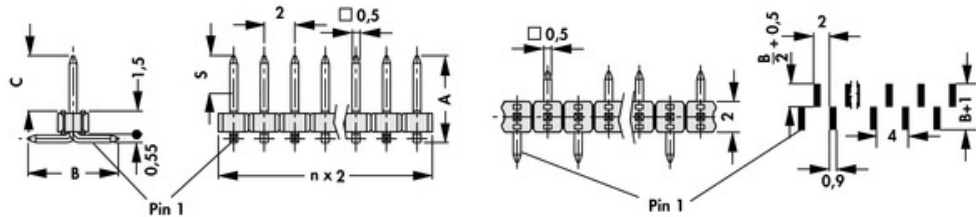

A:	6.5 mm
B:	4.6 mm
C:	4.5 mm
S:	3.5 mm

Equipping

- reel diameter Ø 330 mm

