



Data sheet

LED Furniture built-in universal Dimmer Type 8149

- Pressure two-way switch
- Covers from Berker and other manufacturers fit on this dimmer
- **Leading edge/trailing edge freely selectable**
- Microprocessor controlled
- Adjustable minimum and maximum brightness
- Opportunity for optimized and flicker-free dimming
- Operates quietly



Suitable for:	dimnable LED lamps and LED driver, incandescent and halogen lamps
Rated voltage:	230 V ~ (+/- 10 %), 50 Hz,
Rated power:	5 - 100 W / VA
Rated power LED:	3 - 50 W
Dimensions:	LWH 54 x 54 x 33 mm
Shaft:	∅ 4 mm Metal with soft louvre
Press operation:	on – off
Rotate operation:	dimming
Temperature protection:	Thermal fuse
Overload-/short circuit protection:	electronic
Connection:	Screw terminals up to 2 x 2.5 mm ² (rigid)
Safety class:	IP 20

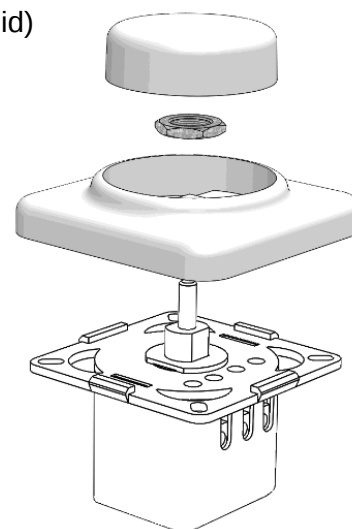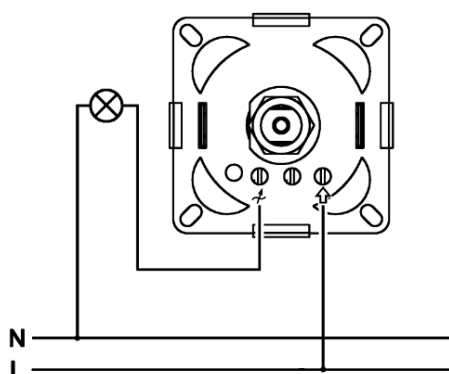

inter BÄR-No.	Version
8149-000...	Dimmer without button + frame
8149-004...	Dimmer with button + frame black
8149-008...	Dimmer with button + frame white

Technical modifications reserved!!!
Works at 230V-mains must only be carried out by a specialist!!!