
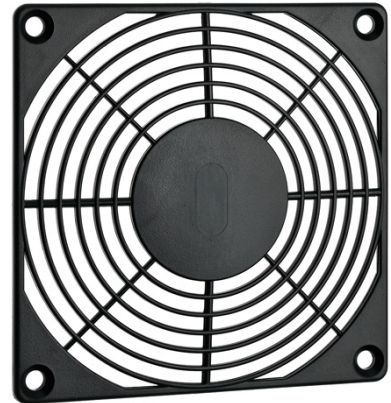


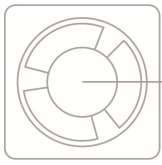

FG120FU

DESCRIPTION

Finger guards for standardized fan sizes 40-150mm.

Mounting: e.g. 4 countersunk-head screws DIN EN 965 M4 or 4 tapping screws DIN 9133 M4
DIN 9133, 3.9

Combination with FSB screen plate for EMC protection possible (EMVG Seite 10)

Certifications	CE
works out for	Fan Guard Plastic
Accessory for fan dimension	120
hole separation [mm]	104,8
mounting hole [mm]	5,5
flamability class	UL94-V0
Ingress protection	IP20
Temp. [°C]	-40 [°C] - 85 [°C]
Base material	Plastic
Weight [kg]	0,02

ORDER INFORMATION

FG120FU 111111851