



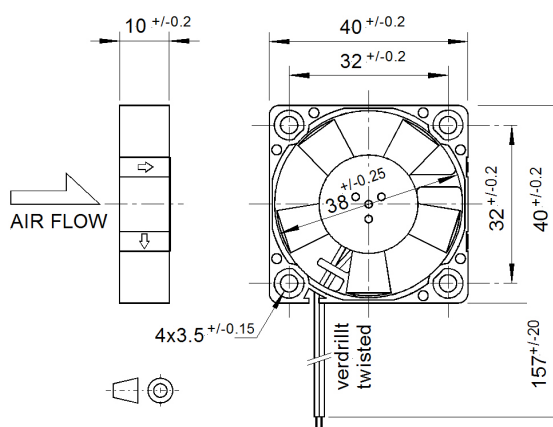

MFB40H12L-003

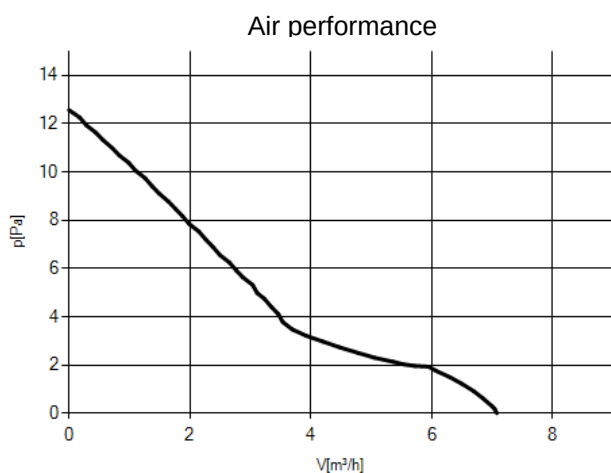

Single wires AWG28, tinned
VCC = red GND = black FG = black
No obstruction within 1mm of air intake

Certifications	CE / WEEE
U [V DC]	12 [V]
I _{typ} [mA]	40 [mA]
I _{max} [mA]	80 [mA]
V _{max} [m³/h]	7,08 [m³/h]
P _{max} [Pa]	13 [Pa]
Noise [dB(A)]	15 [dB(A)]
Rotation Speed [min ⁻¹]	3800 [min ⁻¹]
Signal / FG [Imp/U]	[Imp/U]
PWM	no
Temp. [°C]	-40 [°C] - 85 [°C]
L10/MTTF @ 40°C [h]	70000 [h] - 350000 [h]
Bearing type	Ball bearing
Weight [kg]	0,013

* Noise and rotation speed are subject to deviations due to tolerance.

ORDER INFORMATION

MFB40H12L-003 514082104

Technical changes without notice
06.06.2024

SEPA EUROPE GmbH DE-79427 Eschbach Tel.: +49 7634/59459-0 info@sepa-europe.com