

Data Sheet - TRU Components

BN: 3306034, 3306035

Last updated: 27 Feb 2025


Dia. 16mm, flat round head, 1NO, w/o illumination, quick connect, stainless steel, IP65

BN 3306034 Momentary

BN 3306035 Latching




Drawing:

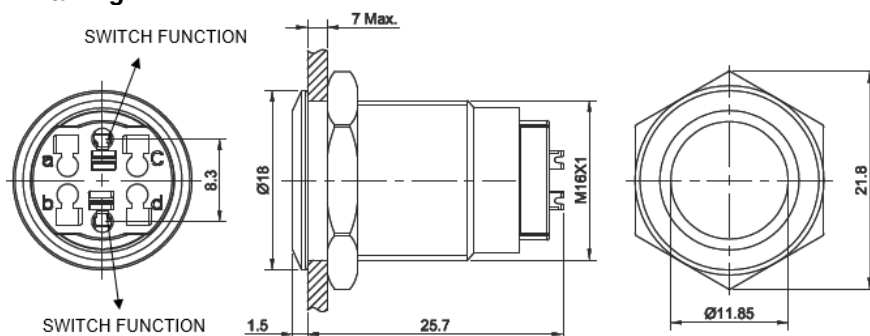

Please insert the wire into the switch function hole

Unit: mm

7MAX: means the panel thickness, the max thickness for the panel no more than 7mm.

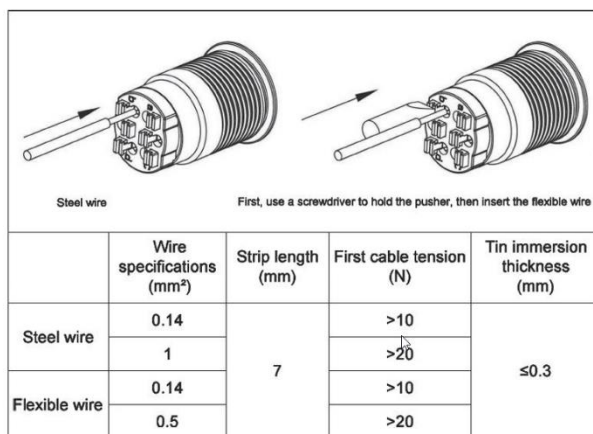



Data Sheet - TRU Components

BN: 3306034, 3306035

Last updated: 27 Feb 2025

BN 3306034 Momentary

BN 3306035 Latching



Technical data:

Switch rating	2A/36VAC/DC
Mounting diameter	16mm
Head shape	Round flat head
Operation type	1NO
Illumination type	Non illumination
Terminal.....	Quick connect
Operating and storage temperature	-25 to +55°C
Operating and storage humidity	45 to 85 % RH
Material	Stainless steel
Mechanical life	1,000,000 (momentary) / 500,000(latching)
Electrical life	50,000 cycles
Dielectric strength	1,500V, RMS 50Hz, 1min.
IP degree	IP65