



Data Sheet - TRU Components

BN: 3306036, 3306037, 3306038, 3306039, 3306040
3306041, 3306042, 3306043, 3306044, 3306045


Last updated: 27 Feb 2025

Dia. 16mm, flat round head, 1NO, ring illumination, quick connect, stainless steel, IP65

	Function	LED color	LED voltage
3306036	Momentary	Red	12V
3306037	Momentary	Green	12V
3306038	Momentary	Yellow	12V
3306039	Momentary	Blue	12V
3306040	Momentary	White	12V
3306041	Latching	Red	12V
3306042	Latching	Green	12V
3306043	Latching	Yellow	12V
3306044	Latching	Blue	12V
3306045	Latching	White	12V



Drawing:

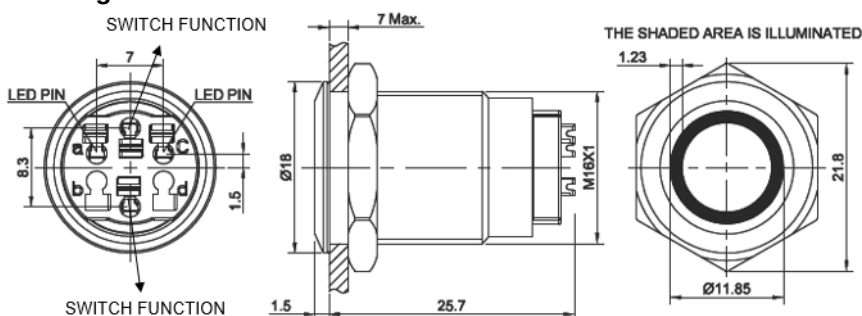

Please insert the wire into a, b, c, d hole

Unit: mm


7MAX: means the panel thickness, the max thickness for the panel no more than 7mm.



Data Sheet - TRU Components

BN: 3306036, 3306037, 3306038, 3306039, 3306040
3306041, 3306042, 3306043, 3306044, 3306045

Last updated: 27 Feb 2025

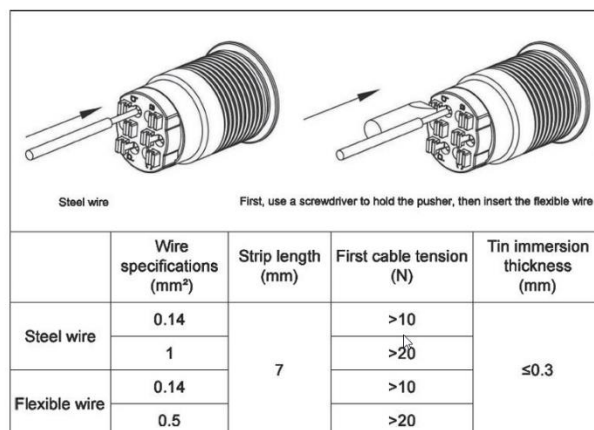

Technical data:

Switch rating.....	2A/36VAC/DC
Mounting diameter	16mm
Head shape	Round flat head
Operation type	1NO
Illumination type	Ring illumination
Terminal.....	Quick connect
Operating and storage temperature	-25 to +55°C
Operating and storage humidity	45 to 85 % RH
Material	Stainless steel
Mechanical life	1,000,000 (momentary) / 500,000(latching)
Electrical life.....	50,000 cycles
Dielectric strength	1,500V, RMS 50Hz, 1min.
IP degree.....	IP65