

VOLTCRAFT - RELIABLE AND PRECISE. SINCE 1982.

For more than 40 years, our product range has been dynamically adapting to the constant changes in the industry. We commit to offering first-class quality to our customers while delivering an excellent cost-performance ratio. This philosophy remains the cornerstone of Voltcraft's success.

26650 LI-ION RECHARGEABLE BATTERY




Item No.:	Qty.
3313978	1

TECHNICAL DATA

Type:	26650
Classification:	Rechargeable
Chemical system:	Lithium-ion
Nominal voltage:	3.7 V
Capacity	5000 mAh
Charge voltage (max.):	4.1V
Charging current (max.):	2.5 A
Terminal voltage:	2.75 V
Discharge current (max.)	15 A
Continuous discharge:	15 A
Terminals:	Flat-top
Weight (approx.):	96 g
Operating conditions:	Charge: 0 to +60 °C Discharge: -20 to +60 °C Humidity: <65 % RH
Storage conditions:	-5 to +35 °C, 0 - 45 % RH
Compliant to:	IEC 62133

*For performance and safety, observe the operating / storage conditions.

DIMENSIONS

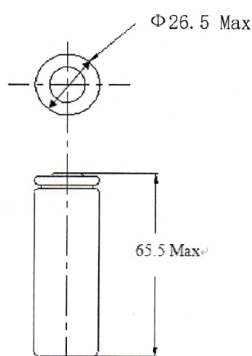

Ø:	26.5 mm
H:	65.5 mm

PERFORMANT CHARACTERISTICS

