


## **BU-P5319**

**(BNC Female to RCA Plug)**

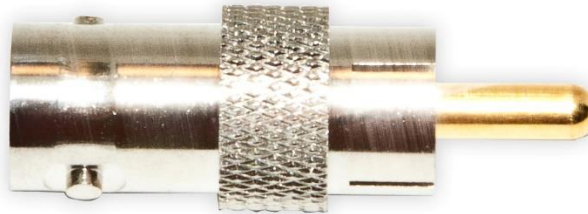

- The BU-P5319 permits a standard BNC cable (male end) to be used with equipment that uses RCA jacks.
- Overall length 1.28" (32.5mm), OD = 0.436" (11.07mm)
- Material:

Body	Nickel-plated brass
Contacts	Gold-plated beryllium copper
RCA Contact	Gold-plated brass
Insulator	PTFE
- Rating:

Impedance	50 Ohms
Frequency	0 to 12.4 GHz
Voltage	Hands-free testing to 500 VRMS
Temperature	-50°C (-58°F) to 105°C (221°F)
- RoHS 3 compliant