


Data Sheet

Vibration Motor 2.4 V 22000 rpm 250 mA

Drawing:

Unit: mm

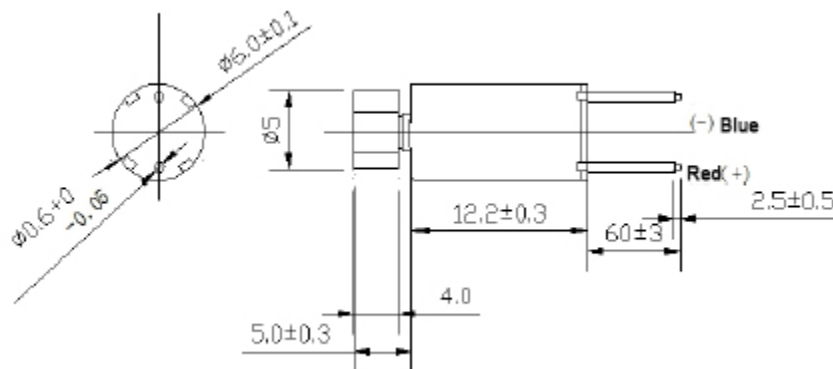

General usage:

The specification applies to the motor used for aeromodelling or toys drive.

Technical data

Rated voltage	2.4 V DC
Rated speed	22000 $\pm$ 15 %rpm
Rated current	250 mA Max.
Operating voltage	1-3 V DC
Working temperature	10 °C~+60 °C
Storage temperature	10 °C~+60 °C
Stall current	80 mA Max.
Starting voltage	0.8 V DC Max.
Insulation resistance	1 M Ω Min.
Mechanical noise	65 dB(A) Max.
Vibration rotation	CW (clockwise) or CCW (contrary clockwise)
Product weight	1.8 g