


Data Sheet

Vibration Motor 3.7 V 12500 rpm 80 mA

Drawing:

Unit: mm

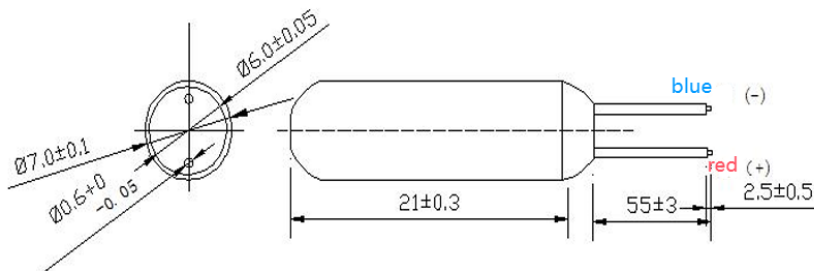

General usage:

The specification applies to the motor used for aeromodelling or toys drive.

Technical data

Rated voltage	3.7 V DC
Rated speed	12500±15 %rpm
Rated current	80 mA Max.
Operating voltage	1.5-4.5 V DC
Working temperature	10 °C~+60 °C
Storage temperature	10 °C~+60 °C
Stall current	80 mA Max.
Starting voltage	0.5 V DC Max.
Insulation resistance	1 MΩ Min.
Mechanical noise	65 dB(A) Max.
Vibration rotation	CW (clockwise) or CCW (contrary clockwise)
Product weight	3.9 g