

DATASHEET

Mini Monocrystalline Solar Panel

Item no.: 3335303	Item no.: 3335306	Item no.: 3335309
Item no.: 3335304	Item no.: 3335307	Item no.: 3335310
Item no.: 3335305	Item no.: 3335308	Item no.: 3335311

Technical data

Item No.:	Dimension (mm)	Thickness (mm)	Power (max.)	Rated Voltage (V.mp)	Rated Current (Imp)	Open Circuit Voltage (Voc)	Short Circuit Current (Isc)	Net Weight approx.
3335303	Ø55	2.5	0.22 W	2 V	0.11 A	2.4 V	0.121 A	7.3 g
3335304	50 x 50	3.1	0.24 W	2 V	0.12 A	2.4 V	0.132 A	5.9 g
3335305	60 x 60	2.7	0.44 W	5.5 V	0.08 A	6.6 V	0.088 A	11.4 g
3335306	80 x 80	2.7	0.96 W	2 V	0.48 A	2.4 V	0.528 A	22 g
3335307	80 x 80	2.7	0.8 W	5 V	0.16 A	6 V	0.176 A	22 g
3335308	30 x 18	2.7	0.05 W	0.5 V	0.1 A	0.6 V	0.11 A	1.6 g
3335309	70 x 33	2.5	0.22 W	5 V	0.044 A	6 V	0.048 A	7.2 g
3335310	90 x 30	2.9	0.33 W	6 V	0.055 A	7.2 V	0.06 A	9.1 g
3335311	100 x 60	2.9	0.792 W	6 V	0.132 A	7.2 V	0.145 A	24 g

Solar cell type Monocrystalline

Power tolerance ±5 %

Operating temperature -20 to +80 °C

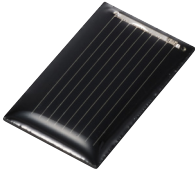
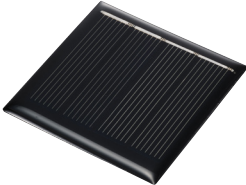
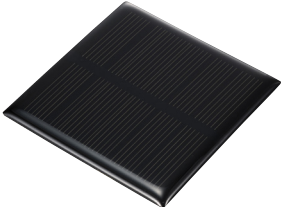
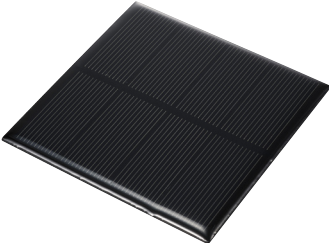
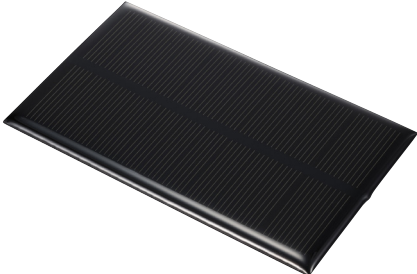
Operating humidity 25 - 95 % RH

Storage temperature -10 to +65 °C

Storage humidity 15 - 75 % RH

Product overview

Images not to scale

Item No.:	Image		Item No.:	Image
3335303			3335308	
3335304			3335309	
3335305			3335310	
3335306			3335311	
3335307	