


Data sheet

Universal LED Line-intermediate Dimmer Type 8136

- Leading edge/trailing edge freely selectable
- For manual operation
- On/off by pressing the rotary knob
- Dimming via rotary wheel
- Adjustable minimum brightness
- With memory effect and soft start
- Simple connection



Suitable for:	dimnable LED lamps. incandescent lamps, high voltage halogen lamps and electronic step-down converter for extra low-voltage incandescent lamps.
Rated voltage:	100 - 240 V ~, 50 / 60 Hz,
Rated power LED:	2 - 60 W
Rated power:	5 - 60 W
Dimensions:	LWH 2 - 60 W
Press operation:	on – off
Rotate operation:	dimming
Connection:	Screw terminals up to 2 x 0.75 mm ²

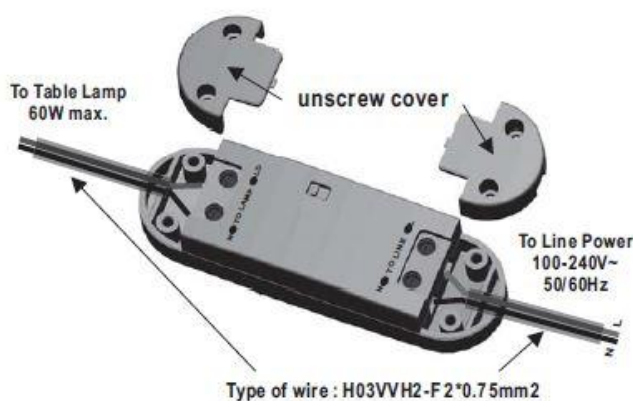

inter BÄR-No.	Version
8136-004...	Dimmer black

Technical modifications reserved!!!
Works at 230V-mains must only be carried out by a specialist!!!