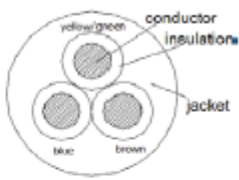


Item No.: 3347295 – Black 50 meter
 3347296 – Black 100 meter
 3368782 – Black 300 meter

Data Sheet

Cable specification				
STYLE		H05RN-F 3G0.75		
Standard		EN50525		
Applications		Medium outdoor cable		
Construction Details:				
Test Item		Unit	3G0.75	
Conductor	Material		Copper	
	Construction		24/0.190±0.005	
	Conductor DC resistance at 20℃ ≤		20℃ ≤26Ω/km	
Core Insulation	Material		EPDM	
	Avg. thickness	mm	0.6	
	Min. thickness	mm	0.44	
	Over Diameter	mm	2.4±0.10	
	Surface		Smooth	
	Colors		yellow/green、brown、blue	
lay	filler		NO	
Jacket	Material		CPE	
	Avg. thickness	mm	0.9	
	Min. thickness	mm	0.67	
	Over Diameter	mm	6.8±0.4	
	Surface		Smooth	
	Colors		BLACK	
Marking			<VDE> 40015999 H05RN-F 300/500V 3G0.75mm2 RIFENG	