



Imou

IMOU SENSE Rex VT Pro

5MP H.265 Wi-Fi Pan & Tilt Camera

With 5MP/3K live monitoring and panoramic 0-355° pan & 0-90° tilt feature, Rex VT ensures every corner of your home completely covered. It supports two-way video calls with a 2.4-inch screen. Two buttons on the side of the screen allow you to place and hang up video calls. Human/Pet detection quickly finds events in images and immediately sends a notification to you. With built-in siren, Rex VT actively keeps unwelcome visitors away from what you care about. Privacy Mode helps protect your personal privacy when you are home, and Smart Tracking function lets the camera follow moving objects when it detects motion. With 2000mAh built-in battery, it can continue working for 30 minutes after power unplug.



H.265 5MP/3K

Sees more than 1080P



Video Intercom

Video calls can be initiated in both on the device side and on the app side



Uninterruptible Work

Uninterruptible Work After Power Cut-off



Privacy Mode

Hides the lens to protect your personal privacy



Active Deterrence

Scare away unwelcome visitors with built-in siren. Customizable Alarm Ringtone.



AI Smart Detection

Quickly finds human/pet targets in your home



24/7 Protection

Infrared night vision for clear-as-day clarity even in pitch dark



Abnormal Sound Alarm

Sends alerts to your smartphone when it detects abnormal sound



Info Display

The Screen can display some information



Diversified Storage

Supports NVR, Cloud Storage or Micro SD card (up to 256GB)




Alarm Clock

Supports setting custom alarms



Smart Tracking

Automatically tracks moving objects

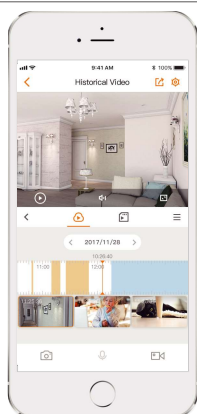

Stay close with what you care


With Cloud service, you will have access to what you care as long as Internet is available. You can record daily or motion videos on Cloud and play back anytime anywhere.

<http://www.imoulife.com>


Imou



Front View

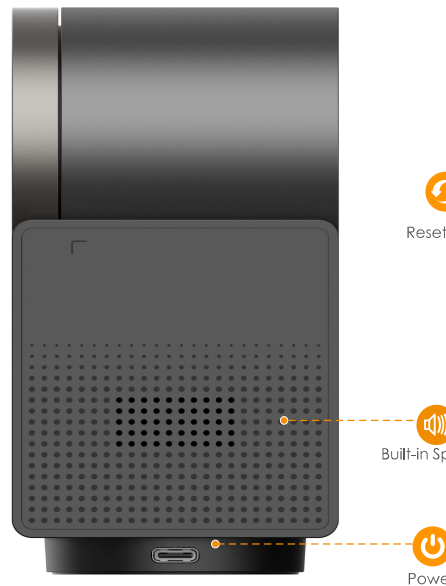

Back View

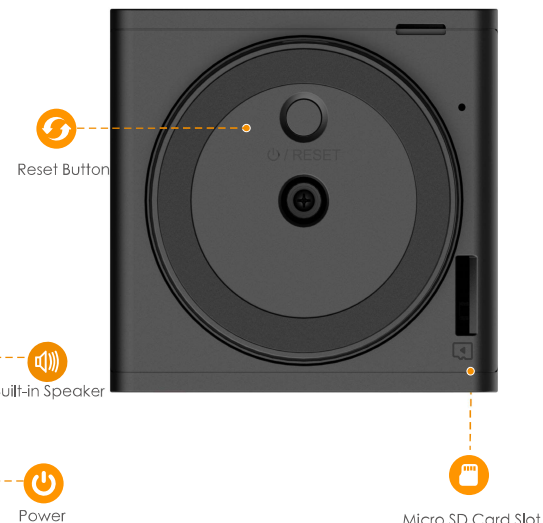

Bottom view

Specifications

Camera

1/3" Progressive CMOS
5MP(2880 x 1620)
Night Vision: 20m(66ft) Distance
3.6mm Fixed Lens
Field of View : 87° (H), 48° (V), 108° (D)
0~355° Pan & 0~90° Tilt
2.4 inch screen
2000mAh battery

Video & Audio

Video Compression : H.265/H.264
Up to 15fps Frame Rate
8 x Digital Zoom
Two-way Audio

Notice Management

Motion Detection
Human Detection
Pet Detection
Configurable Region
Abnormal Sound Alarm

Network

Wi-Fi:IEEE802.11b/g/n, 50m Open Field
Imou App: iOS, Android
Onvif

Auxiliary Interface

Micro SD Card Slot (up to 256GB)
Built-in Mic & Speaker
Reset Button

General

DC 5V1.5A Power Supply
Power Consumption:<7.3W
Working Environment:-10° C~+45° C, Less Than 95%RH
Dimensions: 63 × 60 × 124.5mm (2.48 × 2.36 × 4.9inch)
Weight: 290 g (0.64 lb)
CE UKCA

What's in the box

- 1x Camera
- 1x Quick Start Guide
- 1x Power Adapter
- 1x USB Cable

