 



① Product accessories



90 degree extension sleeve

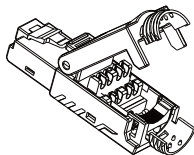


Part 1: 5.5-8.5mm




Copper foil paper

JACK PIN DESIGNATIONS	TIA/EIA T568A	TIA/EIA T568B
	1 White/Green	white/Orange
	2 Green	Orange
	3 white/Orange	White/Green
	4 Blue	Blue
	5 white/Blue	white/Blue
	6 Orange	Green
	7 White/Brown	White/Brown
	8 Brown	Brown


② 2.1 Insert the network cable into the nut from the end

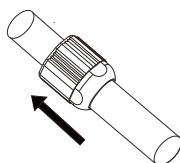


2.2 Peel off the cover of the 1.2 inch network cable

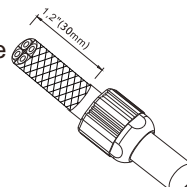




2.3 Fold back braid and drain wire

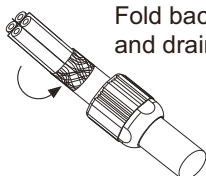


2.4 Wrap a layer of copper foil

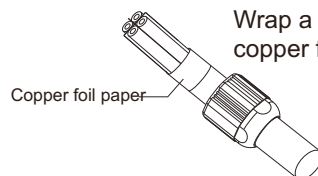


③ Fan out all four twisted pairs, following the color coding label and allocate each conductor into proper slots on wiring cap. Trim the ends of conductors.

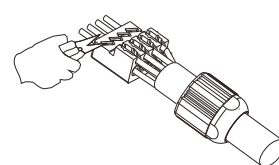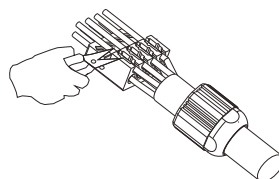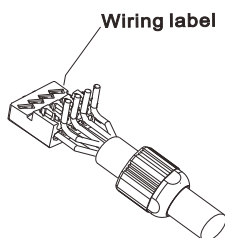


④ Tear off excess stickers along the dotted line.

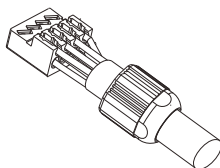



⑤ Place wiring cap on plug.

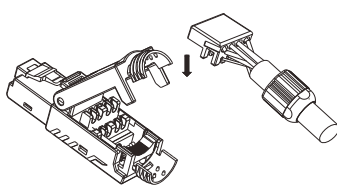

⑥ Place the wiring cap onto plug, use plier to clamp wiring cap until it completely snaps-in to effect the connection.

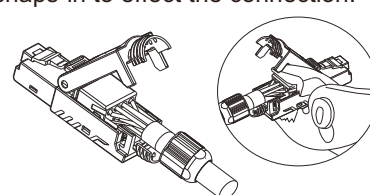

⑦ 7-1 Close the plug cover, make sure the power cord makes proper contact with the ground clip on the plug, and tighten the nut.

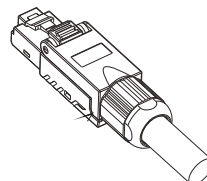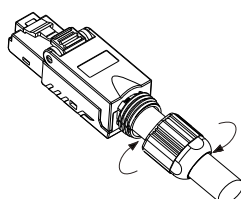

7-2 Close the plug cover, make sure the power cord makes proper contact with the ground clip on the plug, then close 90 degree extending sleeve and tighten the nut.

