



VideoInspector (7,9 mm; 1,5 m)


Professional video inspection system for easy visual inspection of hard-to-reach areas - Wide range of possible applications thanks to compatibility with high-quality camera units

The professional video inspection system is ideal for pinpointing problems behind or in objects, walls, pipes and cavities. The camera head and probe are waterproof and resistant to petrol and diesel. Further advantages are the first-class LED object lighting and the magnetic stand for positioning the base unit. The true-to-life reproduction of colours provides a very realistic image. In addition to the InspectorCamera included in the scope of delivery, the base unit is also compatible with the high-quality InspectorCamera 3DX, 3DL and 3DM camera units. This offers a wide range of possible applications.

- Effective problem localisation behind or in objects, walls, pipes, cavities
- The camera head and probe are waterproof and resistant to petrol and diesel
- 6 high-performance LEDs on the camera for powerful object lighting
- User has both hands free to work thanks to the magnetic stands on the camera unit
- Flexible application options: Compatible with high-quality camera units InspectorCamera 3DX, 3DL and 3DM
- Device fits well in the hand due to ergonomic design
- Various views available on the monitor through rotation and mirroring
- True colours for highly realistic image
- Can also run on mains power

TECHNICAL DATA

Diameter Camera Head	7.9 mm
Camera Resolution	1280 x 720 pixels
Field of View (FOV)	80°
Depth of Focus (DOF)	3 ... 8 cm
Screen Type	3,5" TFT display
Display Resolution	640 x 480 pixels
Image Format	JPEG
Length of Probe	1.5 m
Illumination	4 brightness levels
Digital Zoom	2x digital zoom in 10% increments
Memory	Micro-SD memory card up to 32 GB
Port	USB
Ports	USB type C
Power Supply	Li-ion battery pack 3.7V / 2.8Ah USB type C 5V / 2A
Dimensions (W x H x D)	108 mm x 260 mm x 110 mm x (incl. holder)
Weight	685 g (incl. battery pack)

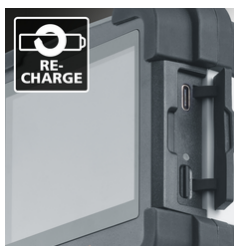

1280 x 720 pixel

LED LIGHT

IP 67

640 x 480 pixel

3,5" colour TFT

IP 54

180°

ZOOM 2x

REC

micro

USB-C

Li-Ion Battery

RECHARGE

HARD

SCOPE OF DELIVERY



Item No. 082.233A

GTIN (EAN) 4021563732197

SU 1