


EV PORTABLE CHARGER

Max 3.7KW - 1 Phase - Type 2

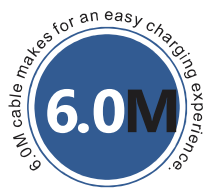

Adjustable Rated Current from 8A to 16A

Delayed start up timer function

SPECIFICATIONS:

Power Phase: 1-Phase
Model No.: P1P6MT2L
Working Voltage: 200V~250V
Rated Current: 8-10-13-16A
Insulation Resistance: >1000MΩ
Resistance Voltage: 2000V
Contact resistance: less than 0.5mΩ
Insertion and Extraction Force: 80N<F<100N

Main Material:

Cable Spec.:

Cable Length:

IP-class:

Fire rating:

Operating Temperature:

Net Weight:

Thermo Plastic/Silicon Rubber
/ CopperAlloy

3*2.5mm²+1*0.75mm²

6m

54

UL94 V-0

(-30°C ~ 50°C)

2.8 kg

DISTRIBUTED BY:

BLP EV SYSTEMS APS - EDITHS ALLÉ 8, 5250 ODENSE SV, DENMARK