 



Cable-Tie Sets 100 pcs. Item-No.: 24CA326 ... 24CA377

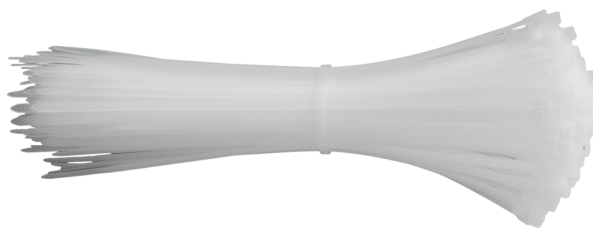

It is impossible to imagine today's world of technology, electronics and mechanics without disposable plastic cable ties. As an inexpensive and reliable connecting and bundling element, the applications go far beyond fixing and bundling cables and cable harnesses! Made of high-purity polyamide, these are very stable and withstand even harsh environments, moisture or UV exposure.



Caution: Cable ties are not suitable for children and should only be used by skilled personnel.

Technical data: Material: Polyamide • Temp-range -20 ... 85 °C • RoHS • REACH • UL94-V2.

Item-No.	Color	Length	Width	Thickness	Loop tensile	Bundle-ø max.	Content	EAN/GTIN
24CA326	White/Nature	100 mm	2.5 mm	0.95 mm	7 kg (69 N)	22 mm	100 pcs.	4260732287926
24CA327	White/Nature	150 mm	2.6 mm	1.05 mm	8 kg (78 N)	35 mm	100 pcs.	4260732287933
24CA328	White/Nature	200 mm	2.6 mm	1.1 mm	8 kg (78 N)	53 mm	100 pcs.	4260732287940
24CA329	White/Nature	250 mm	2.6 mm	1.1 mm	8 kg (78 N)	65 mm	100 pcs.	4260732287957
24CA330	White/Nature	300 mm	2.6 mm	1.1 mm	8 kg (78 N)	80 mm	100 pcs.	4260732287964
24CA331	White/Nature	150 mm	3.6 mm	1.15 mm	9 kg (88 N)	35 mm	100 pcs.	4260732287971
24CA332	White/Nature	200 mm	3.6 mm	1.2 mm	9 kg (88 N)	53 mm	100 pcs.	4260732287988
24CA333	White/Nature	250 mm	3.6 mm	1.2 mm	9 kg (88 N)	65 mm	100 pcs.	4260732287995
24CA334	White/Nature	300 mm	3.6 mm	1.2 mm	9 kg (88 N)	80 mm	100 pcs.	4260732288008
24CA335	White/Nature	350 mm	3.6 mm	1.2 mm	9 kg (88 N)	95 mm	100 pcs.	4260732288015
24CA336	White/Nature	400 mm	3.6 mm	1.2 mm	9 kg (88 N)	108 mm	100 pcs.	4260732288022
24CA337	White/Nature	450 mm	4 mm	1.2 mm	18 kg (177 N)	130 mm	100 pcs.	4260732288039
24CA338	White/Nature	500 mm	4 mm	1.2 mm	18 kg (177 N)	150 mm	100 pcs.	4260732288046
24CA339	White/Nature	200 mm	4.6 mm	1.2 mm	20 kg (196 N)	53 mm	100 pcs.	4260732288053
24CA340	White/Nature	250 mm	4.6 mm	1.2 mm	20 kg (196 N)	65 mm	100 pcs.	4260732288060
24CA341	White/Nature	300 mm	4.6 mm	1.2 mm	20 kg (196 N)	80 mm	100 pcs.	4260732288077
24CA342	White/Nature	300 mm	5.1 mm	1.25 mm	22 kg (216 N)	80 mm	100 pcs.	4260732288084
24CA343	White/Nature	400 mm	5.1 mm	1.25 mm	22 kg (216 N)	108 mm	100 pcs.	4260732288091
24CA344	White/Nature	450 mm	5.1 mm	1.25 mm	22 kg (216 N)	130 mm	100 pcs.	4260732288107
24CA345	White/Nature	500 mm	5.1 mm	1.25 mm	22 kg (216 N)	150 mm	100 pcs.	4260732288114
24CA346	White/Nature	250 mm	7.6 mm	1.45 mm	55 kg (540 N)	65 mm	100 pcs.	4260732288121
24CA347	White/Nature	300 mm	7.6 mm	1.45 mm	55 kg (540 N)	80 mm	100 pcs.	4260732288138
24CA348	White/Nature	350 mm	7.6 mm	1.45 mm	55 kg (540 N)	95 mm	100 pcs.	4260732288145
24CA349	White/Nature	400 mm	7.6 mm	1.45 mm	55 kg (540 N)	108 mm	100 pcs.	4260732288152
24CA350	White/Nature	450 mm	7.6 mm	1.45 mm	55 kg (540 N)	130 mm	100 pcs.	4260732288169
24CA351	White/Nature	500 mm	7.6 mm	1.45 mm	55 kg (540 N)	150 mm	100 pcs.	4260732288176

Black
versions
next
page

 Cable-Tie Sets 100 pcs. Item-No.: 24CA326 ... 24CA377

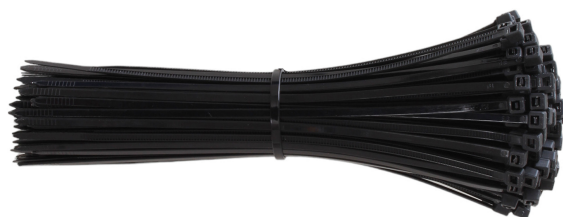

It is impossible to imagine today's world of technology, electronics and mechanics without disposable plastic cable ties. As an inexpensive and reliable connecting and bundling element, the applications go far beyond fixing and bundling cables and cable harnesses! Made of high-purity polyamide, these are very stable and withstand even harsh environments, moisture or UV exposure.

Caution: Cable ties are not suitable for children and should only be used by skilled personnel.

Technical data: Material: Polyamide • Temp-range -20 ... 85 °C • RoHS • REACH • UL94-V2.

Item-No.	Color	Length	Width	Thickness	Loop tensile	Bundle-ø max.	Content	EAN/GTIN
24CA352	Black	100 mm	2.5 mm	0.95 mm	7 kg (69 N)	22 mm	100 pcs.	4260732288183
24CA353	Black	150 mm	2.6 mm	1.05 mm	8 kg (78 N)	35 mm	100 pcs.	4260732288190
24CA354	Black	200 mm	2.6 mm	1.1 mm	8 kg (78 N)	53 mm	100 pcs.	4260732288206
24CA355	Black	250 mm	2.6 mm	1.1 mm	8 kg (78 N)	65 mm	100 pcs.	4260732288213
24CA356	Black	300 mm	2.6 mm	1.1 mm	8 kg (78 N)	80 mm	100 pcs.	4260732288220
24CA357	Black	150 mm	3.6 mm	1.15 mm	9 kg (88 N)	35 mm	100 pcs.	4260732288237
24CA358	Black	200 mm	3.6 mm	1.2 mm	9 kg (88 N)	53 mm	100 pcs.	4260732288244
24CA359	Black	250 mm	3.6 mm	1.2 mm	9 kg (88 N)	65 mm	100 pcs.	4260732288251
24CA360	Black	300 mm	3.6 mm	1.2 mm	9 kg (88 N)	80 mm	100 pcs.	4260732288268
24CA361	Black	350 mm	3.6 mm	1.2 mm	9 kg (88 N)	95 mm	100 pcs.	4260732288275
24CA362	Black	400 mm	3.6 mm	1.2 mm	9 kg (88 N)	108 mm	100 pcs.	4260732288282
24CA363	Black	450 mm	4 mm	1.2 mm	18 kg (177 N)	130 mm	100 pcs.	4260732288299
24CA364	Black	500 mm	4 mm	1.2 mm	18 kg (177 N)	150 mm	100 pcs.	4260732288305
24CA365	Black	200 mm	4.6 mm	1.2 mm	20 kg (196 N)	53 mm	100 pcs.	4260732288312
24CA366	Black	250 mm	4.6 mm	1.2 mm	20 kg (196 N)	65 mm	100 pcs.	4260732288329
24CA367	Black	300 mm	4.6 mm	1.2 mm	20 kg (196 N)	80 mm	100 pcs.	4260732288336
24CA368	Black	300 mm	5.1 mm	1.25 mm	22 kg (216 N)	80 mm	100 pcs.	4260732288343
24CA369	Black	400 mm	5.1 mm	1.25 mm	22 kg (216 N)	108 mm	100 pcs.	4260732288350
24CA370	Black	450 mm	5.1 mm	1.25 mm	22 kg (216 N)	130 mm	100 pcs.	4260732288367
24CA371	Black	500 mm	5.1 mm	1.25 mm	22 kg (216 N)	150 mm	100 pcs.	4260732288374
24CA372	Black	250 mm	7.6 mm	1.45 mm	55 kg (540 N)	65 mm	100 pcs.	4260732288381
24CA373	Black	300 mm	7.6 mm	1.45 mm	55 kg (540 N)	80 mm	100 pcs.	4260732288398
24CA374	Black	350 mm	7.6 mm	1.45 mm	55 kg (540 N)	95 mm	100 pcs.	4260732288404
24CA375	Black	400 mm	7.6 mm	1.45 mm	55 kg (540 N)	108 mm	100 pcs.	4260732288411
24CA376	Black	450 mm	7.6 mm	1.45 mm	55 kg (540 N)	130 mm	100 pcs.	4260732288428
24CA377	Black	500 mm	7.6 mm	1.45 mm	55 kg (540 N)	150 mm	100 pcs.	4260732288435