


Cable Gland Sets, PG Thread Item-No.: 24CA378 ... 24CA416

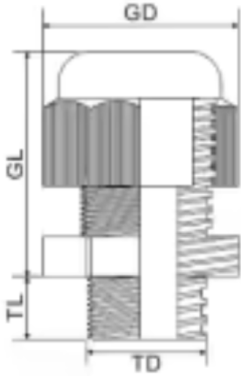

Black



Grey



White


Cable glands in PG design enable cables to be safely fed in and out of enclosures or machines. They protect the transition from the inside to the outside against dirt, dust and moisture and at the same time provide strain relief for the cable. This polyamide 6.6 version is highly resistant to external influences and can cover a wide operating temperature range.

Technical data: Material: Polyamide 6.6 / Seal: NBR • Temp-range -20 ... 80 °C • Thread type: PG • RoHS • REACH • IP68.

Part-No.	Thread	Cable range (∅)	Thread length (TL)	Thread diameter (TD)	Length (GL)	Outside Diameter (GD)	Color	Content	EAN / GTIN
24CA378	PG7	3.5 - 6 mm	6 mm	12 mm	27 mm	16 mm	Black	10 pcs.	4260732288442
24CA379	PG9	4 - 8 mm	6.5 mm	13.5 mm	29 mm	19 mm	Black	10 pcs.	4260732288459
24CA380	PG11	5 - 10 mm	7 mm	16.9 mm	32 mm	21.5 mm	Black	10 pcs.	4260732288466
24CA381	PG13.5	6 - 12 mm	8 mm	18.5 mm	33 mm	23.5 mm	Black	10 pcs.	4260732288473
24CA382	PG16	10 - 14 mm	9 mm	21 mm	33 mm	26 mm	Black	10 pcs.	4260732288480
24CA383	PG19	12 - 15 mm	9.5 mm	23 mm	34 mm	28.5 mm	Black	10 pcs.	4260732288497
24CA384	PG21	13 - 18 mm	9.5 mm	27 mm	38.5 mm	31.5 mm	Black	10 pcs.	4260732288503
24CA385	PG25	15 - 22 mm	10 mm	28 mm	38.5 mm	35 mm	Black	10 pcs.	4260732288510
24CA386	PG29	18 - 25 mm	12.5 mm	35 mm	44 mm	41.2 mm	Black	10 pcs.	4260732288527
24CA387	PG7 PG9 PG13.5 PG19 PG25 (10 pcs./each)	3.5 - 25 mm	6 - 10 mm	12 - 28 mm	27 - 38.5 mm	16 - 35 mm	Black	50 pcs.	4260732288534
24CA388	PG7 PG9 PG11 PG13.5 PG16 (10 pcs./each)	3.5 - 14 mm	6 - 9 mm	12 - 21 mm	27 - 33 mm	16 - 26 mm	Black	50 pcs.	4260732288541
24CA389	PG7 PG7 PG9 PG11 PG13.5 (10 pcs./each)	3.5 - 12 mm	6 - 8 mm	12 - 18.5 mm	27 - 33 mm	16 - 23.5 mm	Black	50 pcs.	4260732288558
24CA390	PG7 PG7 PG9 PG9 PG13.5 (10 pcs./each)	3.5 - 12 mm	6 - 8 mm	12 - 18.5 mm	27 - 33 mm	16 - 23.5 mm	Black	50 pcs.	4260732288565
24CA391	PG7	3.5 - 6 mm	6 mm	12 mm	27 mm	16 mm	Grey	10 pcs.	4260732288572
24CA392	PG9	4 - 8 mm	6.5 mm	13.5 mm	29 mm	19 mm	Grey	10 pcs.	4260732288589
24CA393	PG11	5 - 10 mm	7 mm	16.9 mm	32 mm	21.5 mm	Grey	10 pcs.	4260732288596
24CA394	PG13.5	6 - 12 mm	8 mm	18.5 mm	33 mm	23.5 mm	Grey	10 pcs.	4260732288602
24CA395	PG16	10 - 14 mm	9 mm	21 mm	33 mm	26 mm	Grey	10 pcs.	4260732288619
24CA396	PG19	12 - 15 mm	9.5 mm	23 mm	34 mm	28.5 mm	Grey	10 pcs.	4260732288626

Continuation on the next page

Cable Gland Sets, PG Thread Item-No.: 24CA378 ... 24CA416

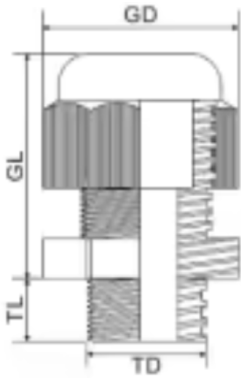

Black



Grey



White

Cable glands in PG design enable cables to be safely fed in and out of enclosures or machines. They protect the transition from the inside to the outside against dirt, dust and moisture and at the same time provide strain relief for the cable. This polyamide 6.6 version is highly resistant to external influences and can cover a wide operating temperature range.

Technical data: Material: Polyamide 6.6 / Seal: NBR • Temp-range -20 ... 80 °C • Thread type: PG • RoHS • REACH • IP68.

Part-No.	Thread	Cable range (Ø)	Thread length (TL)	Thread diameter (TD)	Length (GL)	Outside Diameter (GD)	Color	Content	EAN / GTIN
24CA397	PG21	13 - 18 mm	9.5 mm	27 mm	38.5 mm	31.5 mm	Grey	10 pcs.	4260732288633
24CA398	PG25	15 - 22 mm	10 mm	28 mm	38.5 mm	35 mm	Grey	10 pcs.	4260732288640
24CA399	PG29	18 - 25 mm	12.5 mm	35 mm	44 mm	41.2 mm	Grey	10 pcs.	4260732288657
24CA400	PG7 PG9 PG13.5 PG19 PG25 (10 pcs./each)	3.5 - 25 mm	6 - 10 mm	12 - 28 mm	27 - 38.5 mm	16 - 35 mm	Grey	50 pcs.	4260732288664
24CA401	PG7 PG9 PG11 PG13.5 PG16 (10 pcs./each)	3.5 - 14 mm	6 - 9 mm	12 - 21 mm	27 - 33 mm	16 - 26 mm	Grey	50 pcs.	4260732288671
24CA402	PG7 PG7 PG9 PG11 PG13.5 (10 pcs./each)	3.5 - 12 mm	6 - 8 mm	12 - 18.5 mm	27 - 33 mm	16 - 23.5 mm	Grey	50 pcs.	4260732288688
24CA403	PG7 PG7 PG9 PG9 PG13.5 (10 pcs./each)	3.5 - 12 mm	6 - 8 mm	12 - 18.5 mm	27 - 33 mm	16 - 23.5 mm	Grey	50 pcs.	4260732288695
24CA404	PG7	3.5 - 6 mm	6 mm	12 mm	27 mm	16 mm	White	10 pcs.	4260732288701
24CA405	PG9	4 - 8 mm	6.5 mm	13.5 mm	29 mm	19 mm	White	10 pcs.	4260732288718
24CA406	PG11	5 - 10 mm	7 mm	16.9 mm	32 mm	21.5 mm	White	10 pcs.	4260732288725
24CA407	PG13.5	6 - 12 mm	8 mm	18.5 mm	33 mm	23.5 mm	White	10 pcs.	4260732288732
24CA408	PG16	10 - 14 mm	9 mm	21 mm	33 mm	26 mm	White	10 pcs.	4260732288749
24CA409	PG19	12 - 15 mm	9.5 mm	23 mm	34 mm	28.5 mm	White	10 pcs.	4260732288756
24CA410	PG21	13 - 18 mm	9.5 mm	27 mm	38.5 mm	31.5 mm	White	10 pcs.	4260732288763
24CA411	PG25	15 - 22 mm	10 mm	28 mm	38.5 mm	35 mm	White	10 pcs.	4260732288770
24CA412	PG29	18 - 25 mm	12.5 mm	35 mm	44 mm	41.2 mm	White	10 pcs.	4260732288787
24CA413	PG7 PG9 PG13.5 PG19 PG25 (10 pcs./each)	3.5 - 25 mm	6 - 10 mm	12 - 28 mm	27 - 38.5 mm	16 - 35 mm	White	50 pcs.	4260732288794
24CA414	PG7 PG9 PG11 PG13.5 PG16 (10 pcs./each)	3.5 - 14 mm	6 - 9 mm	12 - 21 mm	27 - 33 mm	16 - 26 mm	White	50 pcs.	4260732288800
24CA415	PG7 PG7 PG9 PG11 PG13.5 (10 pcs./each)	3.5 - 12 mm	6 - 8 mm	12 - 18.5 mm	27 - 33 mm	16 - 23.5 mm	White	50 pcs.	4260732288817
24CA416	PG7 PG7 PG9 PG9 PG13.5 (10 pcs./each)	3.5 - 12 mm	6 - 8 mm	12 - 18.5 mm	27 - 33 mm	16 - 23.5 mm	White	50 pcs.	4260732288824