


Cable-Clips Sets w. Ratchet-Lock 25 pcs. Item-No.: 24CA445 ... 24CA454

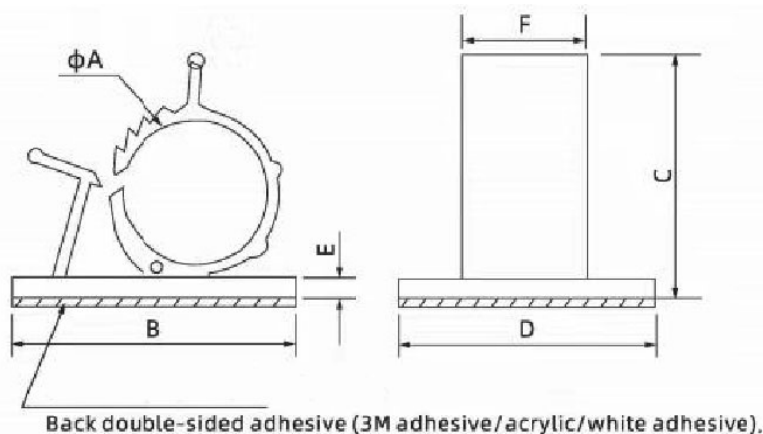

Technical Data: Material: Polyamide (PA66) • Color: Black or White • Bundle-Diameter (A): 7.9 ... 25 mm • Adhesive tape: 3M quality adhesive tape • Content: 25 pcs. • Temperature range: -20 ... +80 °C.

Part-No.	Description	Color	A	B	C	D	E	F	Content	EAN/GTIN
24CA445	Cable-Clip - Ratchet-Lock 7.9-10.3 mm	White	7.9...10.3 mm	25.4 mm	22.2 mm	19.1 mm	1.6 mm	10.2 mm	25 pcs.	4260732289371
24CA446	Cable-Clip - Ratchet-Lock 10-12.8 mm	White	10...12.8 mm	31.8 mm	27.8 mm	19.1 mm	1.6 mm	10.2 mm	25 pcs.	4260732289388
24CA447	Cable-Clip - Ratchet-Lock 12.6-15.4 mm	White	12.6...15.4 mm	36.4 mm	31.8 mm	18.5 mm	3 mm	12 mm	25 pcs.	4260732289395
24CA448	Cable-Clip - Ratchet-Lock 16.5-20.1 mm	White	16.5...20.1 mm	41.5 mm	45.5 mm	25 mm	3 mm	12.7 mm	25 pcs.	4260732289401
24CA449	Cable-Clip - Ratchet-Lock 22.2-25 mm	White	22.2...25 mm	41 mm	44.5 mm	21.5 mm	3 mm	11.5 mm	25 pcs.	4260732289418
24CA450	Cable-Clip - Ratchet-Lock 7.9-10.3 mm	Black	7.9...10.3 mm	25.4 mm	22.2 mm	19.1 mm	1.6 mm	10.2 mm	25 pcs.	4260732289425
24CA451	Cable-Clip - Ratchet-Lock 10-12.8 mm	Black	10...12.8 mm	31.8 mm	27.8 mm	19.1 mm	1.6 mm	10.2 mm	25 pcs.	4260732289432
24CA452	Cable-Clip - Ratchet-Lock 12.6-15.4 mm	Black	12.6...15.4 mm	36.4 mm	31.8 mm	18.5 mm	3 mm	12 mm	25 pcs.	4260732289449
24CA453	Cable-Clip - Ratchet-Lock 16.5-20.1 mm	Black	16.5...20.1 mm	41.5 mm	45.5 mm	25 mm	3 mm	12.7 mm	25 pcs.	4260732289456
24CA454	Cable-Clip - Ratchet-Lock 22.2-25 mm	Black	22.2...25 mm	41 mm	44.5 mm	21.5 mm	3 mm	11.5 mm	25 pcs.	4260732289463

Clean surface well before application. Smooth surface must be clean and dry - first test in an inconspicuous place.
Basic strength immediately after application - Final strength after 24 h.