



# Einhell

**PROFESSIONAL****Cordless Hedge Trimmer****GP-CH 18/61 Li BL-Solo****Item No.: 3410935**

Ident No.: 21013

Bar Code: 4006825673623

The Einhell Professional cordless hedge trimmer GP-CH 18/61 Li BL-Solo combines power and flexibility. The tool is driven by a PurePOWER brushless motor for enhanced power and longer runtimes. Once you register online, the brushless motor has a 10-year warranty. Two speed settings, ECO & MAX POWER mode, power the precise laser-cut and diamond-ground steel blades with a cutting length of 61 cm. The anti-lock braking system ensures optimum safety at work. The removable clippings collector makes it possible to remove the clippings quickly. Delivery includes a sturdy quiver to protect the blade. Battery and charger not included.

## Features & Benefits

- Part of the Power X-Change family, 1 x 18 V battery required
- Brushless motor – more power and longer running time
- PurePOWER brushless – 10-year motor warranty with registration
- Laser-cut and diamond-ground steel blades
- Ergonomic, slim front handle with micro switch
- Anti-blocking system for optimal safety at work
- 2-step speed regulation for adapted work
- Rotating handle for comfortable cutting
- Cuttings collector
- Shock protection to protect the knives
- Aluminium blade cover
- Incl. protective sleeve to protect the blade
- Comes without battery or charger (sold separately)




## Technical Data

- |                         |                        |
|-------------------------|------------------------|
| - Cutting length        | 610 mm                 |
| - Blade length          | 670 mm                 |
| - Spacing between teeth | 26 mm                  |
| - Cuts per minute       | 3000 min <sup>-1</sup> |



## Logistic Data

- |                                      |                     |
|--------------------------------------|---------------------|
| - Product weight                     | 2.81 kg             |
| - Gross weight single packaging      | 4.3 kg              |
| - Dimensions single packaging        | 1133 x 258 x 184 mm |
| - Pieces per export carton           | 4 Pieces            |
| - Gross weight export carton         | 17 kg               |
| - Dimensions Export Carton           | 1150 x 535 x 260 mm |
| - Container quantity (20"/40"/40"HC) | 640   1408   1584   |

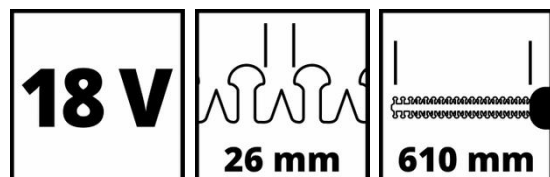

## Available as special accessories



4-6 Ah Multi-Ah Power X-Change Plus Battery  
Item No.: 4511502  
Bar Code: 4006825644210



4,0 Ah Power X-Change Battery  
Item No.: 4511396  
Bar Code: 4006825610376  
Einhell Accessory



2x2 Power X-Quattrocharger 4A Charger  
Item No.: 4512102  
Bar Code: 4006825649536  
Einhell Accessory



2x 5,2Ah & Twincharger Kit PXC-Starter-Kit  
Item No.: 4512108  
Bar Code: 4006825652376  
Einhell Accessory



18V 3,0 Ah Power-X-Change 1 Battery  
Item No.: 4511341  
Bar Code: 4006825590593  
Einhell Accessory



2x 4,0Ah & Twincharger Kit 1 PXC-Starter-Kit  
Item No.: 4512112  
Bar Code: 4006825655766  
Einhell Accessory



5,2Ah & 4A Fastcharger PXC-Starter-Kit  
Item No.: 4512114  
Bar Code: 4006825656787  
Einhell Accessory



2x18V 4,0Ah PXC-Twinpack CB A1 Battery  
Item No.: 4511489  
Bar Code: 4006825638578



18V 5-8Ah Multi-Ah PXC Plus Battery  
Item No.: 4511600  
Bar Code: 4006825665055  
Einhell Accessory



5,2 Ah Power X-Change Plus Battery  
Item No.: 4511437  
Bar Code: 4006825616606  
Einhell Accessory



2,0 Ah Power X-Change Battery  
Item No.: 4511395  
Bar Code: 4006825610369  
Einhell Accessory



18V 2,5Ah PXC Starter Kit PXC-Starter-Kit  
Item No.: 4512097  
Bar Code: 4006825646962  
Einhell Accessory



18V 4,0Ah PXC Starter Kit A1 PXC-Starter-Kit  
Item No.: 4512042  
Bar Code: 4006825613704  
Einhell Accessory



Power X-Fastcharger 4A Charger  
Item No.: 4512103  
Bar Code: 4006825650228  
Einhell Accessory



Power X-Twincharger 3A Charger  
Item No.: 4512069  
Bar Code: 4006825629729  
Einhell Accessory



Power X-Car Charger 3A Charger  
Item No.: 4512113  
Bar Code: 4006825655377  
Einhell Accessory



2x 18V 5,2Ah PXC-Twinpack Battery  
Item No.: 4511526  
Bar Code: 4006825656695  
Einhell Accessory



PXC Battery Mounting Gadget PXC-Battery Accessory  
Item No.: 4514155  
Bar Code: 4006825658774  
Einhell Accessory



3,0 Ah Power X-Change Plus Battery  
Item No.: 4511501  
Bar Code: 4006825644197  
Einhell Accessory



18V 4-6Ah & 6A Boostcharger PXC-Starter-Kit  
Item No.: 4512143  
Bar Code: 4006825667653  
Einhell Accessory



18V 4,0Ah Power-X-Change Plus Battery  
Item No.: 4511553  
Bar Code: 4006825660869  
Einhell Accessory



18V Battery Charger 3,0A - PXC Charger  
Item No.: 4514095  
Bar Code: 4006825655292  
Einhell Accessory

# Battery-Running-Times

| One Battery for All | <br>running time <sup>1</sup><br>(min.) | <br>running time <sup>2</sup><br>(min.) |
|---------------------|--------------------------------------------------------------------------------------------------------------------------|----------------------------------------------------------------------------------------------------------------------------|
|                     |                                                                                                                          |                                                                                                                            |
| 1.5 Ah              | 29.5                                                                                                                     | 20                                                                                                                         |
| 2.0 Ah              | 39                                                                                                                       | 27                                                                                                                         |
| 2.5 Ah              | 49                                                                                                                       | 33                                                                                                                         |
| 3.0 Ah              | 59                                                                                                                       | 40                                                                                                                         |
| 4.0 Ah              | 78                                                                                                                       | 53                                                                                                                         |
| 5.2 Ah              | 102                                                                                                                      | 69                                                                                                                         |
| 6.0 Ah              | 118                                                                                                                      | 80                                                                                                                         |
| 8.0 Ah              | 156                                                                                                                      | 106                                                                                                                        |

Test setup:

- 1) no-load - ECO
- 2) no-load - BOOST