


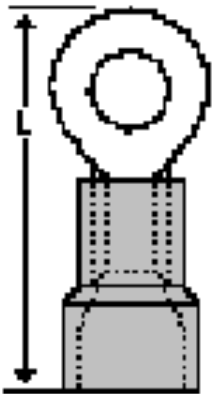

Part Number : [190670369](#)
Product Description : NylaKrimp Funnel Entry
Ring Tongue Terminal for 4/0 AWG Wire, Stud
Size 5/16" (M8)
Series Number : 19067
Status : Active
Product Category : Ring and Spade Terminals
Engineering Number : L-995-56



Documents & Resources

Drawings
[190670369_sd.pdf](#)

3D Models and Design Files
[190670369_stp.zip](#)

Specifications
[PS-19902-011-001.pdf](#)
[PS-19902-013-001.pdf](#)
[PS-19902-016-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	Not Relevant
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2023)8585-DC (23 Jan 2024)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements
- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Ring and Spade Terminals
Series	19067
Description	NylaKrimp Funnel Entry Ring Tongue Terminal for 4/0 AWG Wire, Stud Size 5/16" (M8)
Keyword	Ring Terminal, Ring Terminals
Product Name	NylaKrimp
Type	Ring
UPC	822350727082

Physical

Barrel Type	Closed - Brazed
Insulation	Nylon (PA)
Material - Plating Mating	Tin
Net Weight	51.570/g
Packaging Type	Bag
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Stud Size	5/16" (M8)
Termination Interface Style	Crimp or Compression
Wire Insulation Diameter	23.98mm max.
Wire Size (AWG)	4/0

Application Tooling

Global

Description	Part Number
Die Set (Large) for the HHLS Hydraulic Crimper	<u>192890031</u>

This document was generated on Feb 26, 2025