


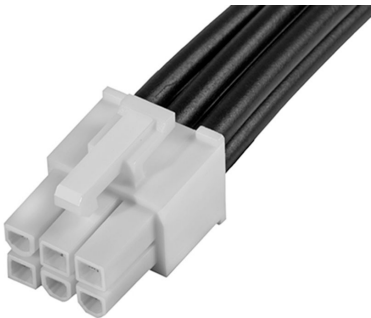

**Part Number :** [2153262062](#)  
**Product Description :** Mini-Fit Jr. Female-to-Pigtail Off-the-Shelf (OTS) Cable Assembly, Dual Row, 300.00mm Length, Gold (Au) Plating, 6 Circuits, Black  
**Series Number :** 215326  
**Status :** Active  
**Product Category :** Power and Signal Cable Assemblies



## Documents & Resources

**Drawings**  
[2153262062\\_sd.pdf](#)

**3D Models and Design Files**  
[2153262062\\_stp.zip](#)

## Product Environment Compliance

### Compliance

|                    |                                                                                       |
|--------------------|---------------------------------------------------------------------------------------|
| GADSL/IMDS         | Not Relevant                                                                          |
| China RoHS         |  |
| EU ELV             | Not Relevant                                                                          |
| Low-Halogen Status | Not Low-Halogen per IEC 61249-2-21                                                    |
| REACH SVHC         | Not Contained per D(2024)6225-DC (07 Nov 2024)                                        |
| EU RoHS            | Compliant per EU 2015/863                                                             |

### Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

### Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474

## Part Details

### General

|                        |                                                                                                                                    |
|------------------------|------------------------------------------------------------------------------------------------------------------------------------|
| Status                 | Active                                                                                                                             |
| Category               | Power and Signal Cable Assemblies                                                                                                  |
| Series                 | 215326                                                                                                                             |
| Description            | Mini-Fit Jr. Female-to-Pigtail Off-the-Shelf (OTS) Cable Assembly, Dual Row, 300.00mm Length, Gold (Au) Plating, 6 Circuits, Black |
| Application            | Power, Wire-to-Board, Wire-to-Wire                                                                                                 |
| Assembly Configuration | Single Ended Connector                                                                                                             |
| Connector to Connector | Mini-Fit Jr.-to-Pigtail                                                                                                            |
| Product Name           | Mini-Fit Jr.                                                                                                                       |
| Type                   | Discrete Wire Assembly                                                                                                             |
| UPC                    | 193264590162                                                                                                                       |

### Electrical

|                               |      |
|-------------------------------|------|
| Current - Maximum per Contact | 9.0A |
| Voltage - Maximum             | 600V |

### Physical

|                                |                |
|--------------------------------|----------------|
| Cable Length                   | 300.00mm       |
| Circuits (Loaded)              | 6              |
| Circuits (maximum)             | 6              |
| Color - Resin                  | Black          |
| Gender                         | Female-Pigtail |
| Lock to Mating Part            | Yes            |
| Material - Metal               | Brass          |
| Material - Plating Mating      | Gold           |
| Material - Plating Termination | Tin            |
| Material - Resin               | Nylon          |
| Net Weight                     | 42.724/g       |
| Number of Rows                 | 2              |

|                             |                      |
|-----------------------------|----------------------|
| Overmolded                  | No                   |
| Packaging Type              | Bag                  |
| Pitch - Mating Interface    | 4.20mm               |
| Plating min - Mating        | 0.762µm              |
| Plating min - Termination   | 0.762µm              |
| Single Ended                | Yes                  |
| Termination Interface Style | Crimp or Compression |
| Wire/Cable Type             | UL 1015              |
| Wire Insulation Diameter    | 1.80-3.10mm          |
| Wire Size (AWG)             | 16                   |

---

## Mates With / Use With

### Mates with Part(s)

| Description                               | Part Number  |
|-------------------------------------------|--------------|
| Mini-Fit BMI Right-Angle Dual Row Headers | <u>42404</u> |
| Mini-Fit BMI Vertical Dual Row Headers    | <u>42440</u> |
| Mini-Fit BMI Right-Angle Dual Row Headers | <u>43810</u> |
| Mini-Fit BMI Vertical Dual Row Headers    | <u>44068</u> |
| Mini-Fit Jr. Dual Row Test Plugs          | <u>44281</u> |
| Mini-Fit Jr. Plug Housings                | <u>5559</u>  |
| Mini-Fit Jr. Vertical Headers             | <u>5566</u>  |
| Mini-Fit Jr. Right-Angle Headers          | <u>5569</u>  |
| Mini-Fit Jr. Dual Row Headers             | <u>87427</u> |