

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1805800101](#)
Status: **Active**
Overview: LED Array Holders, Dual-Ended Wire Trap
Description: LED Array Holder for 16.00 by 19.00mm COB, Rectangular Version, Gold (Au) Plating, PBT, One-Piece Design, White

Documents:
[3D Model](#) [Application Specification AS-180328-001-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [Packaging Specification PK-180586-001-001 \(PDF\)](#)
[3D Model \(PDF\)](#) [Test Summary TS-180155-001-001 \(PDF\)](#)
[Product Specification PS-180580-001-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
UL E345583


General
Product Family Solid State Lighting
Series [180580](#)
Array Type Nichia
Beam Angle N/A
Height 4.10mm
Overview [LED Array Holders, Dual-Ended Wire Trap](#)
Product Name Wire Trap Holder
Type LED COB Array Holder
UPC 887191653433

Physical
Base Type N/A
Color Rendering Index (CRI) N/A
Correlated Color Temp (CCT) N/A
Depth 0.90mm
Flammability 94V-0
Lamp Type N/A
Material - Metal Copper Alloy
Mounting Style Screws
Net Weight 8.868/g
Packaging Type Tray

Electrical
Lamp Wattage - Maximum N/A
Lumens N/A
Voltage (Fixture) - Maximum 600V DC
Wiring Style Poke In Wire Traps

Material Info

Reference - Drawing Numbers
Application Specification AS-180328-001-001
Packaging Specification PK-180586-001-001
Product Specification PS-180580-001-001
Sales Drawing SD-180580-001
Test Summary TS-180155-001-001

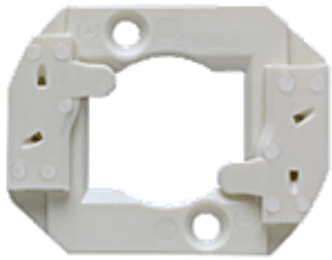

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per -
ECHA_01_2020 (16
January 2020
Halogen-Free
Status
Not Low-Halogen
For more information, please visit [Contact US](#)

China ROHS Green Image
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series
[180580 Series](#)

Use With
19.00mm by 16.00mm COB