


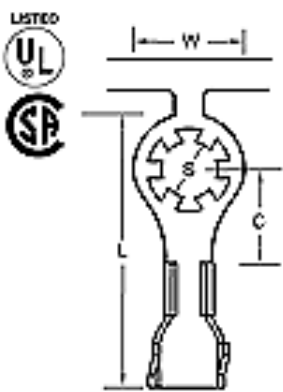

Part Number : [190840007](#)
Product Description : Open Barrel Star Ring ,
Tin-Plated Steel, for 18-14 AWG Wire Range,
Stud Size 6 (M3.5)
Series Number : 19084
Status : Active
Product Category : Ring and Spade Terminals
Engineering Number : SRZ-S-4129-06



Documents & Resources

Drawings
[190840007_sd.pdf](#)

3D Models and Design Files
[190840007_stp.zip](#)

Specifications
[PS-19902-006-001.pdf](#)
[PS-19902-011-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant with Exemption 44
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)6225-DC (07 Nov 2024)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements
- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Ring and Spade Terminals
Series	19084
Description	Open Barrel Star Ring , Tin-Plated Steel, for 18-14 AWG Wire Range, Stud Size 6 (M3.5)
Keyword	Ring Terminal, Ring Terminals
Product Name	N/A
Type	Ring
UPC	800755080216

Agency

CSA	LR18689
UL	E32244

Physical

Barrel Type	Open
Insulation	None
Material - Plating Mating	Tin
Net Weight	0.801/g
Packaging Type	Reel
Stud Size	6 (M3.5)
Termination Interface Style	Crimp or Compression
Wire Size (AWG)	14, 16, 18
Wire Size mm ²	0.80-2.00

Application Tooling

Global

Description	Part Number
Mini-Mac Applicator	<u>638815600</u>