


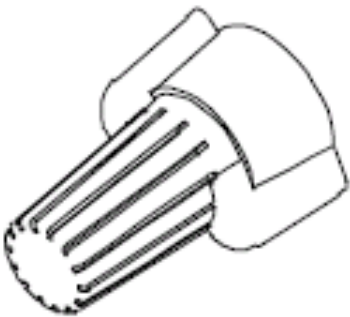

Part Number : [191600194](#)
Product Description : Wing Lock Splice for 28-
2 AWG Wire, Tan
Series Number : 19160
Status : Obsolete
Product Category : Splices
Engineering Number : WL-T



Documents & Resources

Product Environment Compliance

Compliance

GADSL/IMDS	Product not active
China RoHS	Product not active
EU ELV	Product not active
Low-Halogen Status	Product not active
REACH SVHC	Product not active
EU RoHS	Product not active

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Obsolete
Category	Splices
Series	19160
Description	Wing Lock Splice for 28-2 AWG Wire, Tan
Product Name	Wing Lock
UPC	822348112289

Agency

CSA	LR18689
UL	E32244

Electrical

Voltage - Maximum	600V
-------------------	------

Physical

Barrel Type	Closed
Color - Resin	Tan
Flammability	94V-2
Insulation	Nylon (PA)
Material - Metal	Copper
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	2.213/g
Packaging Type	Bag
Temperature Range - Operating	105°C
Wire Insulation Diameter	11.68mm max.
Wire Size (AWG)	10, 12, 14, 16, 18, 20, 22, 24, 26, 8