

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0528920833

Status:

Active

Overview:

Easy-On FFC FPC Connectors

Description:

0.50mm Pitch Easy-On FFC/FPC Connector, Right-Angle, Surface Mount, ZIF, Bottom Contact Style, Cable Retention Guide, 8 Circuits

Documents:

3D Model

Product Specification PS-52892-040-001 (PDF)

3D Model (PDF)

Packaging Specification SPK-52892-001-001 (PDF)

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General

Product Family

FFC/FPC Connectors

Series

52892

Comments

Hinge, Cable Guide

Overview

Easy-On FFC FPC Connectors

Product Name

Easy-On

UPC

887191273716

Physical

Actuator Type

Front Flip

Circuits (Loaded)

8

Color - Resin

Natural

Contact Position

Bottom

Durability (mating cycles max)

20

Mated Height

2.00mm

Material - Metal

Phosphor Bronze

Material - Plating Mating

Tin-Silver-Bismuth

Material - Plating Termination

Tin-Silver-Bismuth

Material - Resin

Nylon

Net Weight

121.272/mg

Number of Rows

1

Orientation

Right Angle

PC Tail Length

2.00mm

PCB Locator

No

PCB Mounting

Surface Mount

PCB Retention

Yes

Packaging Type

Embossed Tape on Reel

Pitch - Mating Interface

0.50mm

Pitch - Termination Interface

0.50mm

Polarized to PCB

No

Stackable

No

Surface Mount Compatible (SMC)

N/A

Temperature Range - Operating

-40° to +85°C

Wire/Cable Type

FFC/FPC

Electrical

Current - Maximum per Contact

0.5A

Voltage - Maximum

50V

Material Info

Reference - Drawing Numbers

Packaging Specification


SPK-52892-001-001

Product Specification

PS-52892-040-001

Sales Drawing

SD-52892-044, SD-52892-045

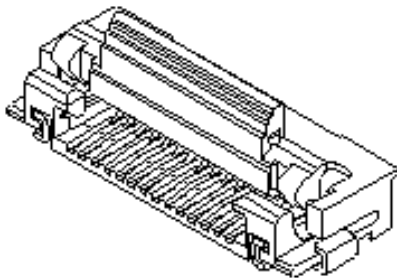

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per -

D(2020)4578-DC (25

June 2020)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit

Contact US

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

52892 Series

This document was generated on 12/01/2020

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION