

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0520300729

Status:


Active

Overview:

FFC-FPC (Through-Hole)

Description:

FFC/FPC Connector, Through-Hole, Vertical, FFC/FPC Connector, ZIF Receptacle, 7 Circuits

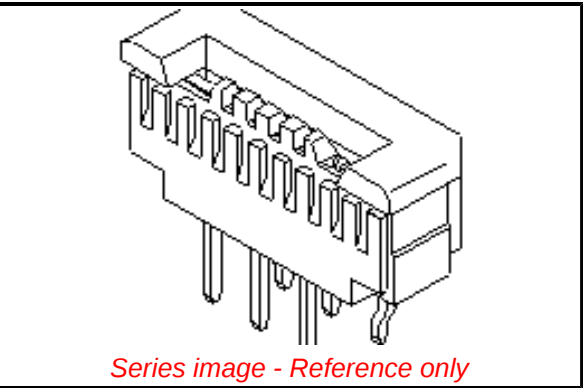

Documents:

3D Model

Drawing (PDF)

Product Specification PS-52030-004-001 (PDF)

Packaging Specification SPK-52030-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E29179
General	
Product Family	FFC/FPC Connectors
Series	52030
Overview	FFC-FPC (Through-Hole)
Product Name	N/A
UPC	822348168941
Physical	
Circuits (Loaded)	7
Contact Position	N/A
Durability (mating cycles max)	30
Entry Angle	Vertical
Mated Height	5.20mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin-Bismuth
Material - Plating Termination	Tin-Bismuth
Material - Resin	Nylon, Polyester
Net Weight	348.001/mg
Number of Rows	1
Orientation	Vertical
PC Tail Length	3.20mm
PCB Retention	Yes
PCB Thickness - Recommended	1.60mm
Packaging Type	Tray
Pitch - Mating Interface	1.00mm
Polarized to PCB	No
Stackable	No
Temperature Range - Operating	-20°C to +80°C
Termination Interface: Style	Through Hole
Wire/Cable Type	FFC/FPC
Electrical	
Current - Maximum per Contact	1.0A
Voltage - Maximum	50V
Material Info	
Reference - Drawing Numbers	
Packaging Specification	SPK-52030-001-001
Product Specification	PS-52030-004-001
Sales Drawing	520301000-000

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -

ED/30/2017 (7 July

2017)

Halogen-Free

Status

Not Low-Halogen

Need more information on product

environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any

non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

52030 Series

Mates With

Molex Premo-Flex FFC. Be sure to match like plating

This document was generated on 08/01/2017

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION