




Part Number : [5055651101](#)
Product Description : 1.25mm Pitch, Micro-Lock Plus Receptacle Crimp Housing, Single Row, Positive Lock, 11 Circuits, Black
Series Number : 505565
Status : Active
Product Category : Connector Housings

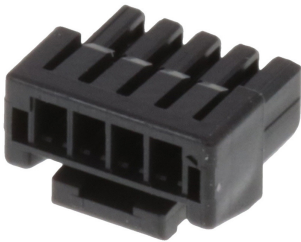

Documents & Resources

Drawings
[5055651101_sd.pdf](#)

3D Models and Design Files
[5055651101.dxf](#)
[5055651101.pdf](#)
[5055651101_stp.zip](#)

Specifications
[5055650000-AS-000.pdf](#)
[5055659200-200.pdf](#)
[5055650000-000.pdf](#)
[5055651000-PS-000.pdf](#)
[5055650002-000.pdf](#)
[5055651002-PS-000.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)6225-DC (07 Nov 2024)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements
- Eu RoHS

- REACH SVHC

- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C

- IPC 1752A Class D

- Molex Product Compliance Declaration

- IEC-62474

- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Connector Housings
Series	505565
Description	1.25mm Pitch, Micro-Lock Plus Receptacle Crimp Housing, Single Row, Positive Lock, 11 Circuits, Black
Application	Signal, Wire-to-Board, Wire-to-Wire
Product Name	Micro-Lock Plus
UPC	889056532020

Agency

UL	E29179
----	--------

Physical

Circuits (maximum)	11
Color - Resin	Black
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	PBT
Net Weight	211.161/mg
Number of Rows	1
Packaging Type	Bag

Panel Mount	No
Pitch - Mating Interface	1.25mm
Pitch - Termination Interface	1.25mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-40° to +105°C

Mates With / Use With

Mates with Part(s)

Description	Part Number
1.25mm Pitch Micro-Lock Plus Vertical, Single Row, Surface Mount Headers	<u>505568</u>
1.25mm Pitch Micro-Lock Plus Right-Angle, Single Row, Surface Mount Headers	<u>505567</u>

Use with Part(s)

Description	Part Number
Pre-Crimped Lead Micro-Lock Plus Female-to-Micro-Lock Plus Female, Tin (Sn) Plating, 150.00mm Length, 26 AWG, Black	<u>797581148</u>
Pre-Crimped Lead Micro-Lock Plus Female-to-Micro-Lock Plus Female, Tin (Sn) Plating, 300.00mm Length, 26 AWG, Black	<u>797581149</u>
Pre-Crimped Lead Micro-Lock Plus Female-to-Micro-Lock Plus Female, Gold (Au) Plating, 150.00mm Length, 26 AWG, Black	<u>797582143</u>
Pre-Crimped Lead Micro-Lock Plus Female-to-Micro-Lock Plus Female, Gold (Au) Plating, 300.00mm Length, 26 AWG, Black	<u>797582144</u>
Micro-Lock Plus Female Crimp Terminals	<u>505431</u>