

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

5035663100

Status:


Active

Overview:

FFC-FPC (SMT)

Description:

0.30mm Pitch FPC Easy-On™ Housing Assembly, 31 Circuits, Mated Height 0.95mm

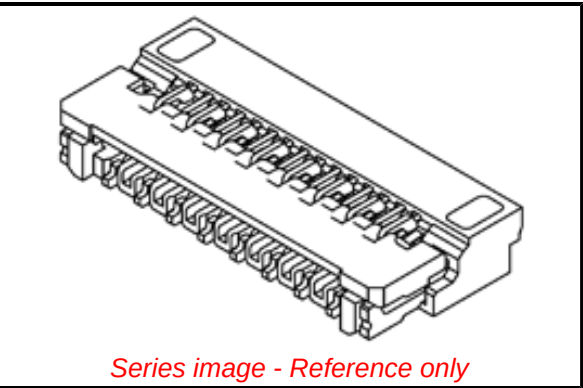

Documents:	
3D Model	Application Specification AS-503566-001-001 (PDF)
Drawing (PDF)	Packaging Specification SPK-503566-001-001 (PDF)
Product Specification PS-503566-001-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E29179
General	
Product Family	FFC/FPC Connectors
Series	503566
Overview	FFC-FPC (SMT)
Product Name	Easy-On™
UPC	884982289215
Physical	
Circuits (Loaded)	31
Circuits (maximum)	31
Color - Resin	Natural
Contact Position	Bottom
Durability (mating cycles max)	10
Entry Angle	Side Entry
Flammability	94V-0
Mated Height	0.95mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold over Nickel
Material - Resin	Polyester Alloy
Net Weight	45.844/mg
Number of Rows	1
Orientation	Right Angle
PCB Locator	No
PCB Retention	None
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.30mm
Polarized to PCB	Yes
Stackable	No
Surface Mount Compatible (SMC)	Yes
Temperature Range - Operating	-40°C to +105°C
Termination Interface: Style	Surface Mount
Wire/Cable Type	FPC only
Electrical	
Current - Maximum per Contact	0.2A
Voltage - Maximum	50V
Material Info	
Reference - Drawing Numbers	
Application Specification	AS-503566-001-001
Packaging Specification	SPK-503566-001-001
Product Specification	PS-503566-001-001
Sales Drawing	SD-503566-001, SD-503566-002

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per - ED/30/2017 (7 July 2017)

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

503566 Series

This document was generated on 09/08/2017

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION