

VOLTCRAFT - RELIABLE AND PRECISE. SINCE 1982.

For more than 40 years, our product range has been dynamically adapting to the constant changes in the industry. We commit to offering first-class quality to our customers while delivering an excellent cost-performance ratio. This philosophy remains the cornerstone of Voltcraft's success.

MSB-532 TEST LEADS




Item no. 3366582	Item no. 3366592
Item no. 3366591	Item no. 3366593

Touch-safe test lead according to IEC 61010 with a stackable 4 mm safety plug. Highly flexible, double-insulated stranded wire with a wear indicator thanks to two-color insulation. The test lead can also be used in the power range for PV, e-drive, and e-mobility applications where CAT IV approval is required. A high safety margin is provided for universal measurement tasks in the laboratory thanks to CAT III 1000 V 32 A.

FEATURES

CAT III 1000V / CAT IV 600V 32A // PA Housing material // PVC cable material // Double insulation cable

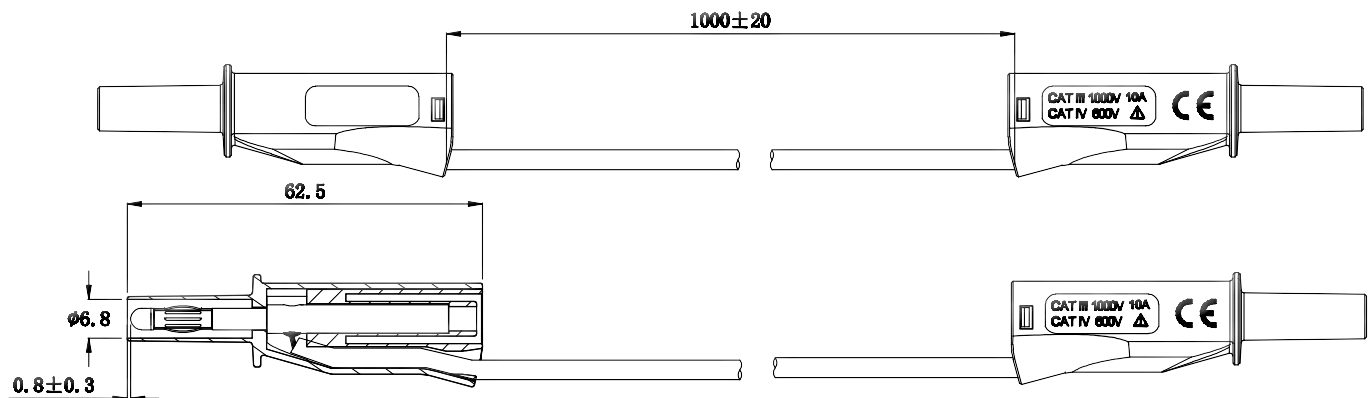

TECHNICAL DATA

PP insulated banana plug	4 mm
Cable material	Silicone PVC
Cable dimension	4.0 mm, 2.5 ² mm
Conductor size	13 AWG
Wire stranding	72 / 0.08 BC x 7 x Ø 4.0 mm
Contact resistance	0.1 ohm
Contact pin	Brass
Contact spring	Copper-beryllium

Housing basic material	UL 94 V-0
Operating conditions	-10 to +50 °C, < 80% RH
Storage conditions	-10 to +50 °C, < 80% RH
Dimensions (L x W x H)	62 x 16.5 x 17.5 mm
Weight	0.04 kg

BN	Cable length	Colours
3366582	1 m	Red
3366591	1 m	Black
3366592	2 m	Red
3366593	2 m	Black

PACKAGE CONTENTS

Test lead