


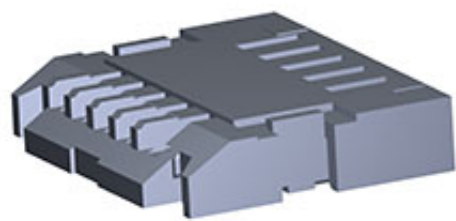

Part Number : 5014610591
Product Description : 0.50mm Pitch Easy-On Back Flip FPC Connector, Right-Angle, Surface Mount, Bottom Contact Style, 0.80mm Mated Height, 5 Circuits
Series Number : 501461
Status : New Business Not Supported
Product Category : FFC / FPC Connectors



Documents & Resources

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant with Exemption 44; 33
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)6225-DC (07 Nov 2024)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	New Business Not Supported
Category	FFC / FPC Connectors
Series	501461
Description	0.50mm Pitch Easy-On Back Flip FPC Connector, Right-Angle, Surface Mount, Bottom Contact Style, 0.80mm Mated Height, 5 Circuits
Product Name	Easy-On
UPC	887191456195

Electrical

Current - Maximum per Contact	0.3A
Voltage - Maximum	50V

Physical

Actuator Type	Back Flip
Circuits (Loaded)	5
Contact Position	Bottom
Durability (mating cycles max)	20
Mated Height	0.80mm
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Net Weight	18.156/mg
Orientation	Right Angle
Packaging Type	Embossed Tape on Reel
PCB Locator	No
PCB Mounting	Surface Mount
PCB Retention	Yes
Pitch - Mating Interface	0.50mm
Polarized to PCB	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C
Wire/Cable Type	FPC only
