


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

|                          |                                                                                                                  |
|--------------------------|------------------------------------------------------------------------------------------------------------------|
| Part Number:             | 5035660900                                                                                                       |
| Status:                  | Active                                                                                                           |
| Overview:                | FFC-FPC (SMT)                                                                                                    |
| Description:             | 0.30mm Pitch Easy-On FPC Connector, 9 Circuits, Mated Height 0.95mm                                              |
| Replacement Part Number: | http://www.molex.com/molex/products/listview.jsp?channel=Products&sType=p&query=50356609002503566-0902 (drop-in) |

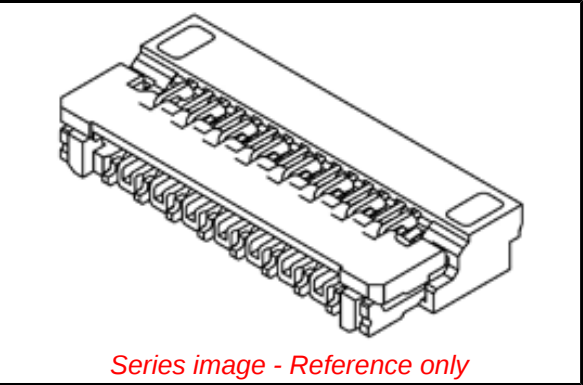

Series image - Reference only

|                                                               |                                                                   |
|---------------------------------------------------------------|-------------------------------------------------------------------|
| Documents:                                                    |                                                                   |
| <a href="#">3D Model</a>                                      | <a href="#">Application Specification AS-503566-001-001 (PDF)</a> |
| <a href="#">Drawing (PDF)</a>                                 | <a href="#">Packaging Specification SPK-503566-001-001 (PDF)</a>  |
| <a href="#">Product Specification PS-503566-001-001 (PDF)</a> | <a href="#">RoHS Certificate of Compliance (PDF)</a>              |

|                                |                       |
|--------------------------------|-----------------------|
| Agency Certification           |                       |
| UL                             | E29179                |
| General                        |                       |
| Product Family                 | FFC/FPC Connectors    |
| Series                         | 503566                |
| Overview                       | FFC-FPC (SMT)         |
| Product Name                   | Easy-On               |
| Replacement Part Number        | 503566-0902 (drop-in) |
| UPC                            | 884982568990          |
| Physical                       |                       |
| Actuator Type                  | Flip                  |
| Circuits (Loaded)              | 9                     |
| Circuits (maximum)             | 9                     |
| Color - Resin                  | Natural               |
| Contact Position               | Bottom                |
| Durability (mating cycles max) | 10                    |
| Flammability                   | 94V-0                 |
| Mated Height                   | 0.95mm                |
| Material - Metal               | Phosphor Bronze       |
| Material - Plating Mating      | Gold over Nickel      |
| Material - Resin               | Polyester Alloy       |
| Net Weight                     | 17.536/mg             |
| Number of Rows                 | 1                     |
| Orientation                    | Right Angle           |
| PCB Locator                    | No                    |
| PCB Mounting                   | Surface Mount         |
| PCB Retention                  | None                  |
| Packaging Type                 | Embossed Tape on Reel |
| Pitch - Mating Interface       | 0.30mm                |
| Polarized to PCB               | Yes                   |
| Stackable                      | No                    |
| Surface Mount Compatible (SMC) | Yes                   |
| Temperature Range - Operating  | -40° to +105°C        |
| Wire/Cable Type                | FPC only              |
| Electrical                     |                       |
| Current - Maximum per Contact  | 0.2A                  |
| Voltage - Maximum              | 50V                   |
| Material Info                  |                       |
| Reference - Drawing Numbers    |                       |
| Application Specification      | AS-503566-001-001     |
| Packaging Specification        | SPK-503566-001-001    |

|                                                                                                                                                                                        |                                                        |
|----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|--------------------------------------------------------|
| EU ELV<br>Compliant                                                                                                                                                                    |                                                        |
| EU RoHS<br>Compliant                                                                                                                                                                   | China RoHS                                             |
| REACH SVHC<br>Not Contained Per -<br>ED/61/2018 (27 June<br>2018)                                                                                                                      |                                                        |
| Halogen-Free<br>Status<br>Low-Halogen                                                                                                                                                  |                                                        |
| Need more information on product<br>environmental compliance?                                                                                                                          |                                                        |
| Email <a href="mailto:productcompliance@molex.com">productcompliance@molex.com</a><br>Please visit the <a href="#">Contact Us</a> section for any<br>non-product compliance questions. |                                                        |
| China ROHS<br>ELV<br>Prop65<br>RoHS Phthalates                                                                                                                                         | Green Image<br>Compliant<br>Compliant<br>Not Contained |

Search Parts in this Series  
503566 Series

This document was generated on 09/10/2018

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**