


61813736	DATA SHEET	
Valid from: 25.07.2022	Ferrule crimping tool PEW	

The PEW crimping tool are for crimping insulated and non-insulated ferrules acc. to DIN 46228.
The crimping tool automatically adjust to the desired crimping cross-section and has always the same results thanks to the completion system.

Technical features:

Material	Spring steel, burnished, with 2K handle
Scope of Application	insulated and non-insulated Ferrules
Cross-section	0,08 up to 16mm ²
TWIN-Ferrule	2x0,25 up to 10mm ²

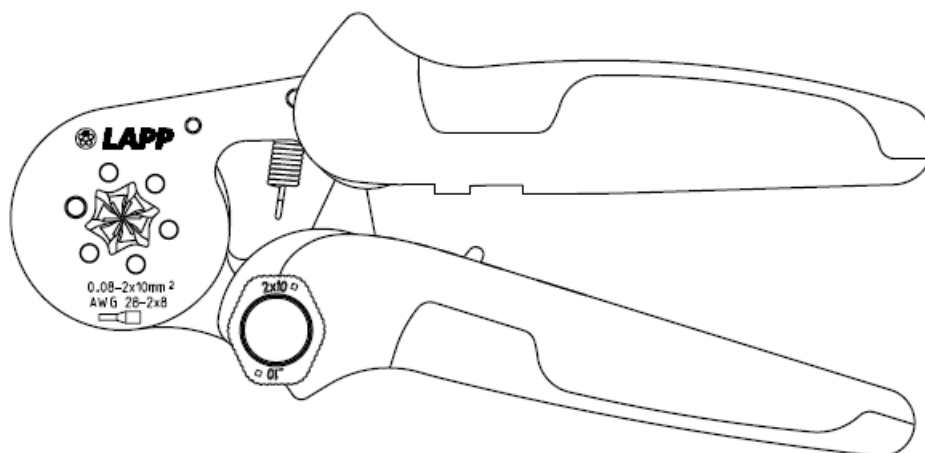

Part No.	Part description	For mm ²	TWIN-Ferrule	Crimp profile
6181 3736	PEW 8.185	0,08 bis 16 mm ²	2x0,25 – 6 mm ²	square
6181 3737	PEW 8.286	0,08 bis 16 mm ²	2x0,25 – 10 mm ²	hexagonal

Creator: MAU1 /PDP Released: DAMU1/PDP	Document: DB61813736EN Version: 00	Page 1 of 1
---	---------------------------------------	-------------