
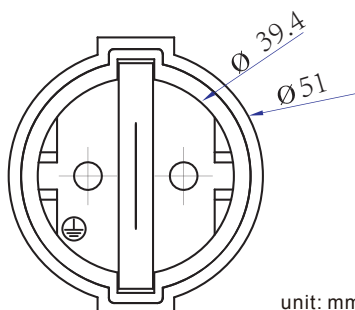
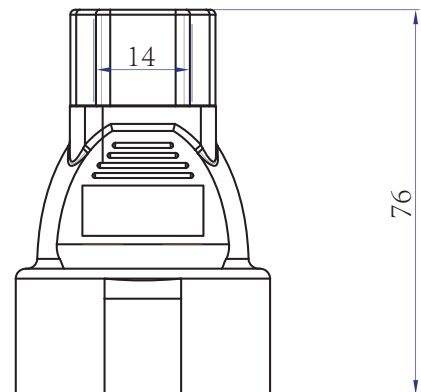
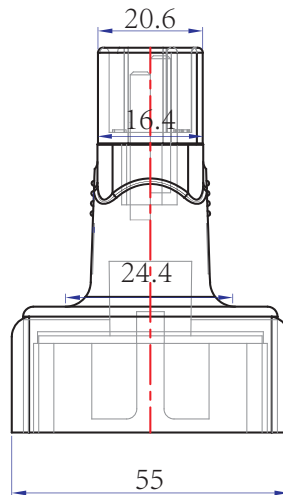
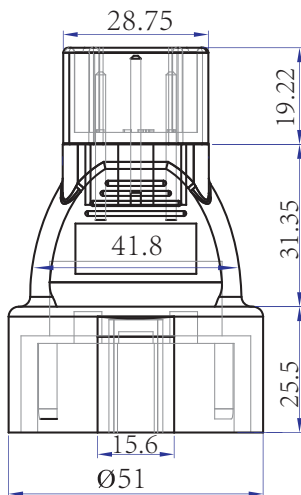
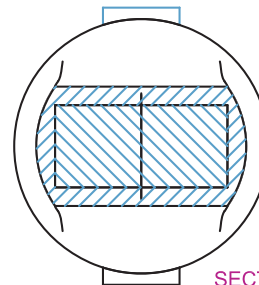


Data Sheet

EUR Schuko CEE to IEC C14 Adapter

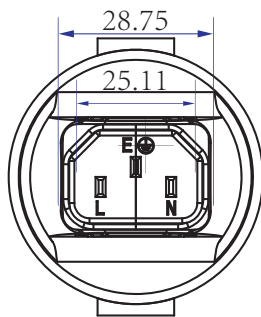

unit: mm
Tolerance: ±1

Specification

Type: CEE7/7 to IEC-320-C14

Material

Insulation: IEC - PC

CEE - PA66

Contact: Phosphor Copper

Voltage Rating: 250 V/AC

Current Rating: 10A

Contact Resistance: <20mΩ

Insulating Resistance: >50MΩ

Operating Temperature: -40°C ~ 85°C

Storage Temperature: 10°~80°C